


Tripp Lite Protects the Patient Room, Wall to Wall

**UL 60601-1
Compliance Required
within 6' Radius of
Patient**

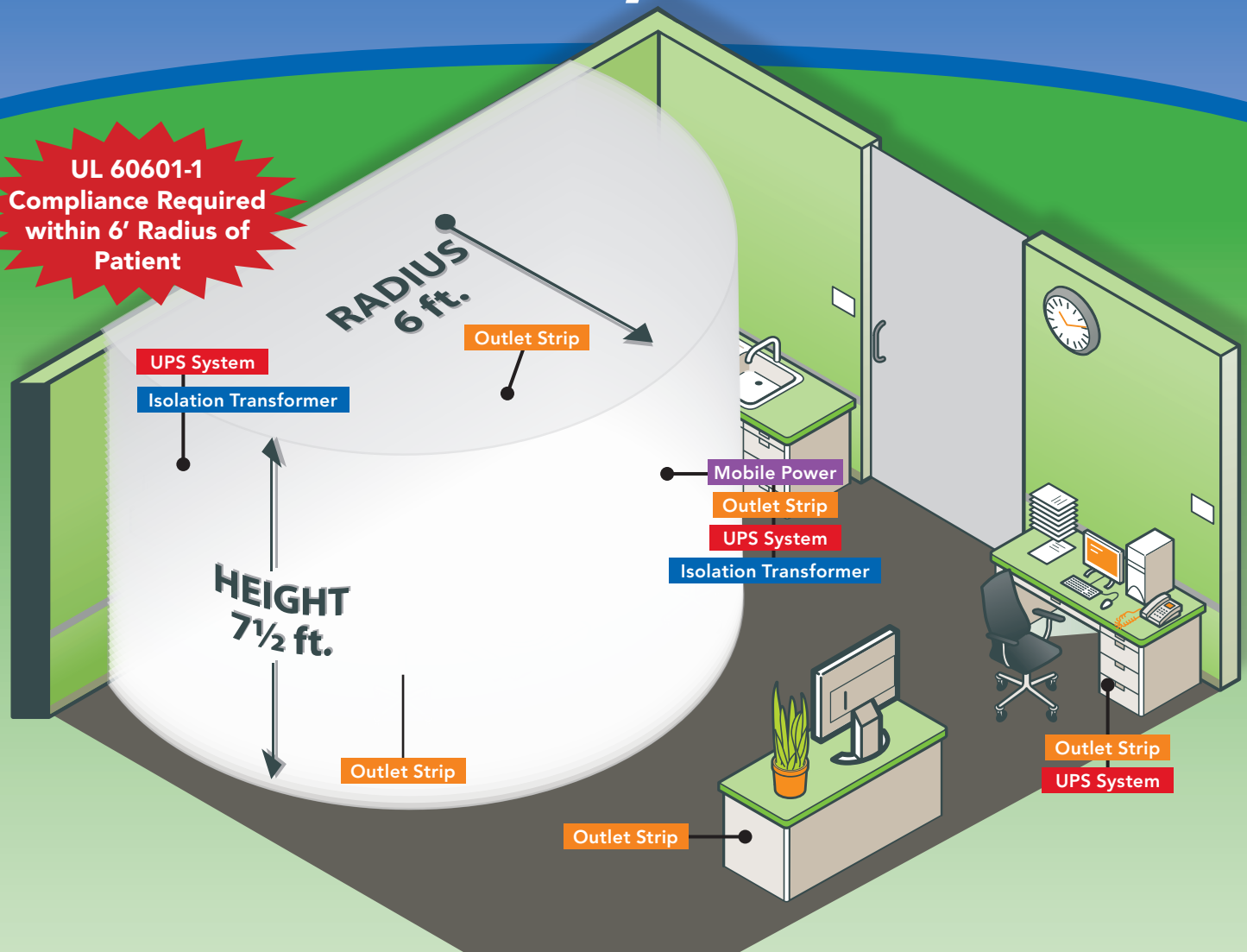

Power Solutions for Every Healthcare Application

UL 60601-1 Medical Grade • Laboratory • IT & Facility • Administration • More



UPS Systems



Isolation Transformers



Outlet Strips



Mobile Power



UL 60601-1 Compliance Made Easy with TRIPP LITE



UPS Systems Medical-Grade

- Meet strict leakage requirements for medical equipment used in nonlife-support applications (UL 60601-1)
- Automatic voltage regulation (AVR) keeps computers working through emergency power checks, low voltage (brownout) and high voltage conditions without using battery power
- Provide portable power to medical staff, rolling computer carts to patient rooms
- Mobile Power Retrofit Kit (Model HCRK) adds AC power source to new or existing carts

Model	Power Rating			Back-Up Time Half/Full Load	NEMA Plug Configuration	Number of Outlets	Dimensions (In.)			Footnotes
	VA	Watts	Volts				W	H	D	
OMNISMART350HG	330	225	120	46/18 min.	5-15P-HG	4	5.25	10.75	7.50	2, 5
SMART700HG	700	450	120	42/18 min.	5-15P-HG	4	7.50	12.50	9.50	2, 3, 5
SMART1200XLHG	1000	750	120	28/10 min.	5-15P-HG	4	7.50	12.75	9.25	1, 2, 3, 4, 5
HCRK	400	300	120	12 hr.	5-15P-HG	3	13.50	18	31	3, 6

(1) Expandible with external battery pack. (2) DB9 serial port. (3) USB communication ports. (4) Includes full featured software with voltage and battery monitoring capability. (5) Hospital-grade plug and receptacles. (6) 10' coiled AC input cord.



Outlet and Surge Strips Medical-Grade

- 4- or 6-outlet design permits multiple pieces of electrical equipment to operate where outlets and space are limited
- Provide versatile power distribution inside the patient-care area
- Allow for replacement of all non-compliant outlet strips
- **SPS415HGULTRA provides surge suppression as well as complete UL 60601-1 compliance**

Model	No. of Outlets	Cord Length (Ft.)	Amps	NEMA Plug Configuration	Material of Construction	Compliance	Dimensions (In.)		
							D	W	H
For Use within Patient-Care Areas									
PS-415-HGULTRA	4	15	15	5-15P-HG	Metal	UL 60601-1	2.5	13.75	1.5
SPS415HGULTRA	4	15	15	5-15P-HG	Metal	UL 60601-1	2.5	13.75	1.5
For Use on Mobile Carts, Instruments and Diagnostic Equipment in Patient-Care Areas									
PS-415-HG-OEM	4	15	15	5-15P-HG	Metal	UL 1363a	2.5	8.65	1.5
PS-615-HG-OEM	6	15	15	5-15P-HG	Metal	UL 1363a	2.5	13.75	1.5



Isolation Transformers Medical-Grade

- Complete line isolation, noise filtering and surge suppression—ideal protection for sensitive equipment in patient-care areas
- Meet UL 60601-1 requirements
- Hospital-grade plug and outlet receptacles
- Less than 100 microamps of leakage for connected loads

Model	Watts	Includes	H	Dimensions (In.)	
				W	D
IS250HG	250	2 Outlets	4.50	4.75	7.75
IS500HG	500	4 Outlets	5.75	6.25	9.25
IS1000HG	1000	4 Outlets	7.25	7.25	10.50
IS1800HG	1800	6 Outlets	7.75	8.25	12.25

To Find the Ideal Solution
for Your Application:
Contact Tripp Lite Today!



Tripp Lite has been a trusted manufacturer of
innovative solutions for over 85 years!

Tripp Lite World Headquarters
1111 W. 35th Street, Chicago, IL 60609
773.869.1234 • www.tripplite.com