

Tripp Lite Targets the Power Needs of Your Entire Healthcare Facility!

Every patient receiving treatment in your facility carries an invisible 6-ft. regulatory perimeter around with them that mandates you use special medical-grade electronic equipment. Only Tripp Lite, trusted for quality and reliability since 1922, provides a full line of power strips to meet the unique regulatory requirements of every sector of your facility.

INSIDE of Patient-Care Areas


Tripp Lite Medical-Grade Power Strip

- The ONLY type of Power Strip allowed by UL and NEC regulations for use within a 6-ft. radius of EVERY patient!
- Reduces cumulative shock potential of connected equipment
- Agency approved to UL 60601-1
- U.S. Patent No. 7,375,939
- Special OEM models approved to UL 1363a for use in patient-care areas when cart/furniture-mounted
- SPS415HGULTRA provides surge suppression as well as complete UL 60601-1 compliance

OUTSIDE of Patient-Care Areas

Tripp Lite Power Strips (with Hospital-Grade Plug & Receptacles)

- Agency approved to UL 1363

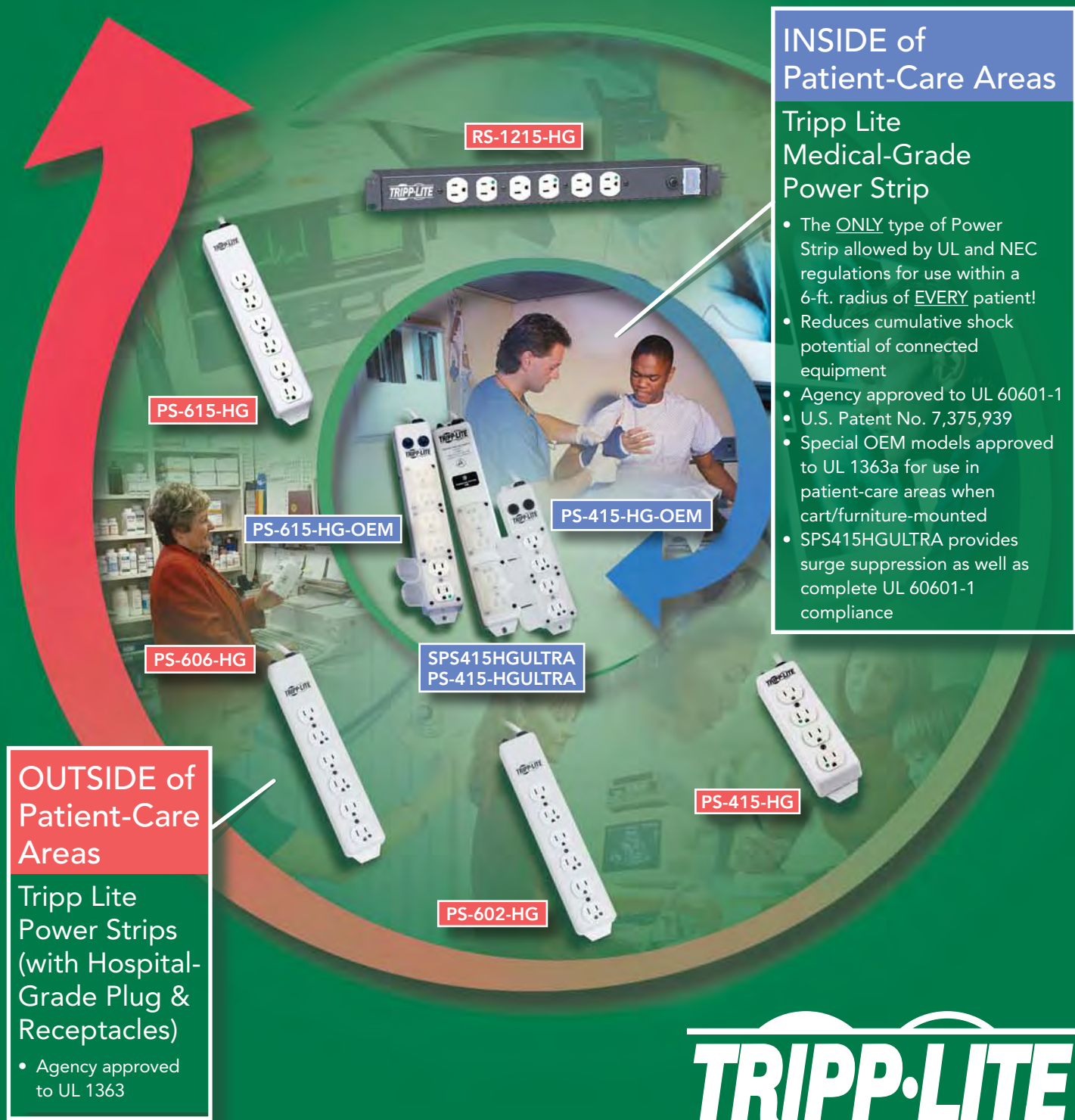

TRIPP·LITE

See back for features and specifications

Only Tripp Lite Offers Power Strips for Use Both Inside and Outside of Patient-Care Areas!

Inside of Patient-Care Areas

Medical-Grade (Agency Approved to UL 60601-1) Power Strips

- Provides UL Compliance for Connected Equipment
- Reduces Cumulative Shock Potential of Connected Equipment
- Offers Convenient Source for Power Distribution
- Includes Hospital-Grade Plug and Receptacles
- U.S. Patent No. 7,375,939
- SPS415HGULTRA provides surge suppression as well as complete UL 60601-1 compliance

Specifications

Model #	Input Voltage (Frequency)	Outlet Quantity	Outlet Type	Housing Construction	Input Cord Length (ft)	Input Plug Type	Unit Dimensions L x W x H (in)	Unit Weight (lb)
PS-415-HGULTRA	120V AC (50/60 Hz)	4	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	3.2
SPS415HGULTRA	120V AC (50/60 Hz)	4	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	3.2



UL certified by:

 60601-1, 60950-1



Inside and/or Outside of Patient-Care Areas, Must be Permanently Mounted if in Patient-Care Area

Medical-Grade (Agency Approved to UL 1363a) Power Strips

- Offers Convenient Source for Power Distribution
- For Use on Mobile Carts and Furniture
- Includes Hospital-Grade Plug and Receptacles

Specifications

Model #	Input Voltage (Frequency)	Outlet Quantity	Outlet Type	Housing Construction	Input Cord Length (ft)	Input Plug Type	Unit Dimensions L x W x H (in)	Unit Weight (lb)
PS-410-HGOEMCC	120V AC (50/60 Hz)	4	NEMA 5-15R-HG (Hospital-Grade)	Metal	10	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	2.25
PS-415-HG-OEM	120V AC (50/60 Hz)	4	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	8.65 x 2.5 x 1.5	4.2
PS-615-HG-OEM	120V AC (50/60 Hz)	6	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	4.3

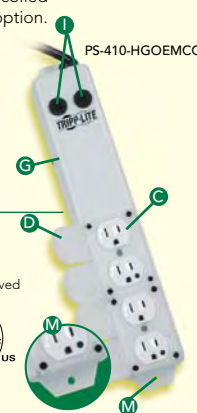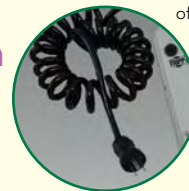

Agency approved

 UL 1363a

Features

- Ⓐ UL 60601-1 Compliant Design (internal)
- Ⓑ Hospital-Grade Plug
- Ⓒ Hospital-Grade Output Receptacles
- Ⓓ Safety Covers
- Ⓔ Patented Technology (internal)
- Ⓕ Diagnostic LED
- Ⓖ Metal Housing
- Ⓗ Mounting Keyholes and Flanges
- Ⓜ Resettable Circuit Breaker
- Ⓝ Grounding Lug
- Ⓚ Removable Rackmount Hardware
- Ⓛ Illuminated Power Switch with Locking Safety Cover
- Ⓜ Permanent-Mount OEM Design




Outside of Patient-Care Areas

Power Strips (with Hospital-Grade Plug & Receptacles)


- Offers Convenient Source for Power Distribution
- Includes Hospital-Grade Plug and Receptacles

Specifications

Model #	Input Voltage (Frequency)	Outlet Quantity	Outlet Type	Housing Construction	Input Cord Length (ft)	Input Plug Type	Unit Dimensions L x W x H (in)	Unit Weight (lb)
PS-415-HG	120V AC (50/60 Hz)	4	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	8.65 x 2.5 x 1.5	2
PS-602-HG	120V AC (50/60 Hz)	6	NEMA 5-15R-HG (Hospital-Grade)	Metal	1.5	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	3.1
PS-606-HG	120V AC (50/60 Hz)	6	NEMA 5-15R-HG (Hospital-Grade)	Metal	6	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	3.5
PS-615-HG	120V AC (50/60 Hz)	6	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	13.75 x 2.5 x 1.5	4.3
RS-1215-HG	120V AC (50/60 Hz)	12*	NEMA 5-15R-HG (Hospital-Grade)	Metal	15	NEMA 5-15P-HG (Hospital-Grade)	4 x 19 x 1.75 (1U)	4.6

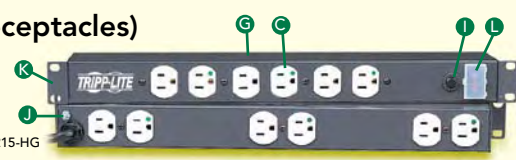

1363
 UL US
 1363
 Certification varies by model.

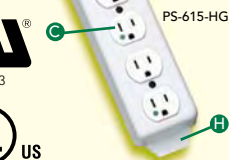

* 6 front-panel outlets and 6 rear-panel outlets.

Tripp Lite Offers a Complete Line of Surge Suppressors!

Visit www.tripplite.com/products/medical for more information.

ISOBAR6ULTRAHG



OVER 85 YEARS
 SINCE 1922
 Manufacturing Excellence

ISO 9001
 CERTIFIED QUALITY SYSTEMS



Tripp Lite World Headquarters:
 1111 W. 35th Street, Chicago, IL 60609
 773.869.1234 • www.tripplite.com

The policy of Tripp Lite is one of continuous improvement. Specifications are subject to change without notice.