
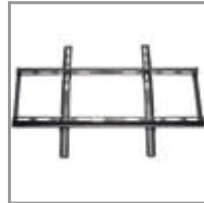


# Fixed Wall-Mount for 32" to 70" Flat-Screen Displays

MODEL NUMBER: DWF3260X

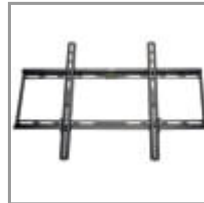

## Description

Tripp Lite's VESA-compliant DWF3260X Fixed Flat-Screen Wall Mount's low-profile design features an open frame for easy wall access and optimal display positioning flexibility. Its durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 165 lbs. and fits most 32- to 70-inch flat-panel displays. It comes with all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs. A built-in bubble level enables accurate display leveling. For peace of mind, the DWF3260X comes backed by a 5-year warranty and green, RoHS-compliant design.

## Features

- Low-profile design features an open frame for easy wall access and optimal display positioning flexibility
- Durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 165 lbs. and fits most 32- to 70-inch flat-panel displays
- Includes all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs
- Built-in bubble level enables accurate display leveling
- 5-year warranty and green
- RoHS-compliant design

## Highlights

- **SEE NEW MODEL - DWF3270X**
- Low-profile mounting keeps unit out of sight for sleek, professional appearance
- Fits most flat-panel displays from 32" to 70"
- Open frame for easy wall access
- Horizontal adjustment compensates for off-center wall studs
- Equipped with a bubble level for accurate display leveling
- Supports up to 165 lbs.
- 5-year warranty

## Package Includes

- DWF3260X Fixed Flat-Screen Wall Mount
- Mounting Hardware
- Owner's Manual

## Specifications

OVERVIEW	
UPC Code	037332178817
PHYSICAL	
Color	Black



Powering Business Worldwide



Material of Construction	Steel
VESA Pattern (mm)	600x400
Motion	Fixed
Mounting Location	Wall
Degrees of Motion	Fixed
Maximum Weight Capacity (lbs.)	165
Maximum Weight Capacity (kg)	75
Shipping Dimensions (hwd / in.)	26.77 x 4.72 x 1.77
Shipping Dimensions (hwd / cm)	68.00 x 11.99 x 4.50
Shipping Weight (lbs.)	5.19
Shipping Weight (kg)	2.35
Unit Dimensions (hwd / in.)	17.130 x 26.140 x 1.180
Unit Weight (lbs.)	5.19
Unit Weight (kg)	2.35
<b>FEATURES &amp; SPECIFICATIONS</b>	
Cord Management	No
Tools Necessary	Yes
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty
Product Warranty Period (U.S. & Canada)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.