


# Full-Motion Wall-Mount for 23" to 55" Flat-Screen Displays

MODEL NUMBER: DWM2342M

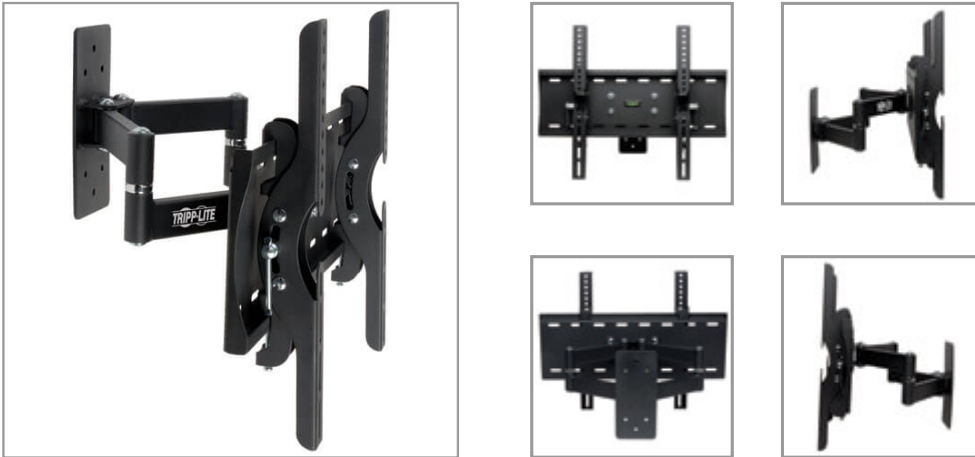

## Description

Tripp Lite's VESA-compliant DWM2342M Full-Motion Flat-Screen Wall Mount offers full-motion articulation and can free up valuable space in your workstation by allowing you to effortlessly reposition your display at any time, even after installation. Its sleek design features convenient one-touch display adjustment with tilt and swivel capabilities and fits most 23- to 55-inch flat-panel displays. Its durable, all-metal frame with scratch-resistant, powder-coat finish withstands the stress of repeated use and blends easily into any décor. It comes with all necessary mounting hardware and supports weights of up to 110 lbs. A built-in bubble level enables accurate display leveling. For peace of mind, the DWM2342M comes backed by a 5-year warranty.

## Features

- Tripp Lite's VESA-compliant DWM2342M Full-Motion Flat-Screen Wall Mount offers full-motion articulation and can free up valuable space in your workstation by allowing you to effortlessly reposition your display at any time, even after installation
- Sleek design features convenient one-touch display adjustment with tilt and swivel capabilities
- Fits most 23- to 55-inch flat-panel displays
- Durable, all-metal frame with scratch-resistant, powder-coat finish withstands the stress of repeated use and blends easily into any décor
- Comes with all necessary mounting hardware and supports weights of up to 110 lb
- Built-in bubble level enables accurate display leveling
- 5-year warranty

## Specifications

OVERVIEW	
UPC Code	037332178855

## Highlights

- SEE NEW MODEL - DWM2655M
- Can be used to increase available desk/table space in office applications
- Fits most flat-panel displays from 23" to 55"
- Convenient one-touch display adjustment for easy view optimization
- Equipped with a bubble level for accurate display leveling
- Wide range of motion with -10° to +10° tilt and 90° swivel capability
- Supports up to 110 lbs.
- 5-year warranty

## Package Includes

- DWM2342M Full-Motion Flat-Screen Wall Mount
- Mounting Hardware
- Owner's Manual



Powering Business Worldwide



PHYSICAL	
Color	Black
Material of Construction	Metal
VESA Pattern (mm)	50x75; 100x100; 200x200; 300x300; 400x400; 500x400
Motion	Full
Mounting Location	Wall
Degrees of Motion	-10/+10 Tilt; 90 Swivel
Maximum Weight Capacity (lbs.)	110
Maximum Weight Capacity (kg)	50
Min/Max Arm Extension (in.)	5.51 min to 19.29 max
Min/Max Arm Extension (cm)	140 min to 490 max
Shipping Dimensions (hwd / in.)	23.42 x 9.72 x 9.06
Shipping Dimensions (hwd / cm)	59.49 x 24.69 x 23.01
Shipping Weight (lbs.)	18.60
Shipping Weight (kg)	8.44
Unit Dimensions (hwd / in.)	7.670 x 16.850 x 16.850
Unit Weight (lbs.)	18.10
Unit Weight (kg)	8.21
FEATURES & SPECIFICATIONS	
Cord Management	No
Tools Necessary	Yes
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty
Product Warranty Period (U.S. & Canada)	5-year limited warranty

1000 Eaton Boulevard  
 Cleveland, OH 44122  
 United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
 Eaton is a registered trademark. All other trademarks  
 are the property of their respective owners.