
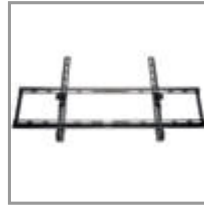


## Tilt Wall-Mount for 37" to 70" Flat-Screen Displays

MODEL NUMBER: DWT3763X

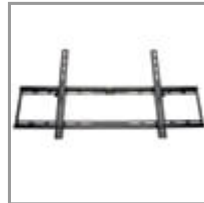

### Description

Tripp Lite's VESA-compliant DWT3763X Tilt Flat-Screen Wall Mount's low-profile design features an open frame for easy wall access and optimal display positioning flexibility. With tilt adjustment for improved viewing angles in applications where the audience is located below the display, it packs a lot of functionality into an unobtrusive frame. It can also free up valuable space in your workstation by allowing you to effortlessly reposition your display at any time, even after installation. Its durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 200 lbs. and fits most 37- to 70-inch flat-panel displays. It comes with all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs. A built-in bubble level enables accurate display leveling. For peace of mind, the DWT3763X comes backed by a 5-year warranty.

### Features

- Tripp Lite's VESA-compliant DWT3763X Tilt Flat-Screen Wall Mount's low-profile design features an open frame for easy wall access and optimal display positioning flexibility
- With tilt adjustment for improved viewing angles in applications where the audience is located below the display, it packs a lot of functionality into an unobtrusive frame
- Free up valuable space in your workstation by repositioning your display at any time, even after installation
- Durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 200 lb
- Fits most 37- to 70-inch flat-panel displays
- It comes with all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs
- Built-in bubble level enables accurate display leveling
- 5-year warranty

## Specifications

### Highlights

- **SEE NEW MODEL - DWT3770X**
- Low-profile mounting keeps unit out of sight for sleek, professional appearance
- Fits most flat-panel displays from 37" to 70"
- Open frame for easy wall access
- Tilt adjustment improves viewing angles in applications where the audience is below the display
- Horizontal adjustment compensates for off-center wall studs
- Wide range of motion with -10° to 0° tilt capability
- Equipped with a bubble level for accurate display leveling
- Supports up to 200 lbs
- 5 year warranty

### Package Includes

- DWT3763X Tilt Flat-Screen Wall Mount
- Mounting Hardware
- Owner's Manual



Powering Business Worldwide



OVERVIEW	
UPC Code	037332178763
PHYSICAL	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	100x100; 200x100; 200x200; 400x200; 400x400; 600x400; 800x400
Motion	Tilt
Mounting Location	Wall
Degrees of Motion	-10/+0 Tilt
Distance from Wall (in.)	1.77
Distance from Wall (cm)	5
Distance from Wall (mm)	45
Maximum Weight Capacity (lbs.)	200
Maximum Weight Capacity (kg)	91
Shipping Dimensions (hwd / in.)	2.17 x 8.46 x 35.04
Shipping Dimensions (hwd / cm)	5.51 x 21.49 x 89.00
Shipping Weight (lbs.)	7.26
Shipping Weight (kg)	3.29
Unit Dimensions (hwd / in.)	17.320 x 34.020 x 1.800
Unit Weight (lbs.)	7.26
Unit Weight (kg)	3.29
FEATURES & SPECIFICATIONS	
Cord Management	No
Tools Necessary	Yes
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty
Product Warranty Period (U.S. & Canada)	5-year limited warranty

1000 Eaton Boulevard  
 Cleveland, OH 44122  
 United States  
<https://triplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
 Eaton is a registered trademark. All other trademarks  
 are the property of their respective owners.