


# 32-Port 2U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel, RJ45 Ethernet, USB, HDMI, Cat5e/6

MODEL NUMBER: N062-032-KJ

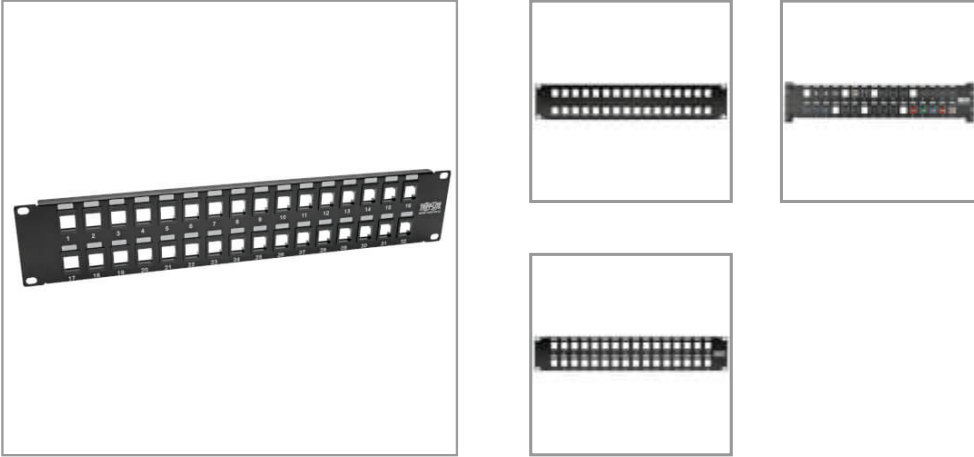

Manages and organizes input and output cable connections in your network. Customizable solution for a variety of applications, including Ethernet, voice, audio/video and USB.

## Description

The N062-032-KJ 32-Port 2U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel manages and organizes the cabling in your network. The 32 blank cutouts accommodate all keystone jacks, including RJ45 Ethernet, HDMI audio/video, voice and USB applications. Ports are clearly numbered to help you identify connections. Mounts easily into 2U of an EIA-standard 19-inch two-post rack or wall-mount rack enclosure. Made from heavy-duty cold-rolled steel. Grounding wire included.

## Features

**Manages and Organizes a Wide Variety of Cabling** 32 blank cutouts accommodate most keystone jacks in the market  
 For use with RJ45 Ethernet, HDMI audio/video, voice, USB and other applications  
 Ports are numbered for easy connection identification  
 Heavy-duty cold-rolled steel construction

**Quick, Easy Installation** Mounts easily into 2U of EIA-standard 19 in. 2-post rack or wall-mount rack enclosure  
 Includes grounding wire

## Highlights

- 32 blank cutouts compatible with all keystone jacks
- For Ethernet, voice, audio/video, USB applications and more
- Heavy-duty cold-rolled steel construction
- Numbered ports for easy connection identification
- Mounts into 2U of standard 19 in. 2-post or wall-mount rack

## Package Includes

- N062-032-KJ 32-Port 2U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel
- Grounding wire

## Specifications

OVERVIEW	
UPC Code	037332193605
Product Type	Rackmount
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDMI; USB 2.0 (High Speed)
CONNECTIONS	
Number of Ports	32
Side A - Connector 1	KEYSTONE JACK CUTOUT



Powering Business Worldwide



Side B - Connector 1	KEYSTONE JACK CUTOUT
<b>PHYSICAL</b>	
Color	Black
Shipping Dimensions (hwd / in.)	0.67 x 1.85 x 19.61
Shipping Dimensions (hwd / cm)	1.70 x 4.70 x 49.81
Shipping Weight (lbs.)	1.40
Shipping Weight (kg)	0.64
Panel Style	Blank
<b>FEATURES &amp; SPECIFICATIONS</b>	
IP68 Rated	No
IP20 Rated	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Warranty Details	LIFETIME LIMITED

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.