
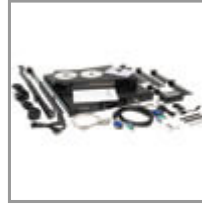


Minicom SmartRack 116 IP - 16-Port Remote Access Console Cat5 KVM with 17" LCD

MODEL NUMBER: 0SU70050

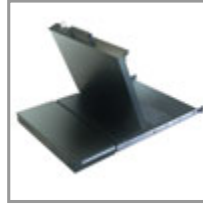

Description

Local and Remote Access

Control More Servers

Slim, 1U Solution that Saves Space

SmartRack 116 IP Key features

Features

- 16 Port KVM
- 17" TFT LCD Display
- Remote or Local Access
- BIOS level access
- Multi-platform – PS/2 and USB support
- Extends distance between servers and switch up to 30 meters/100 feet over Cat5e cable
- Compliant with the Federal Trade Agreement (TAA) for GSA Schedule purchases

Specifications

Highlights

- 16 Port KVM
- 17" TFT LCD Display
- Remote or Local Access
- BIOS level access
- Multi-platform – PS/2 and USB support
- Extends distance between servers and switch up to 30 meters/100 feet over Cat5e cable
- Compliant with the Federal Trade Agreement (TAA) for GSA Schedule purchases

System Requirements

Operating System

- Compatible with Windows, Linux, Unix and all other major operating systems

Resolution

- Supports video resolutions up to 1280 x 1024

Package Includes

- SmartRack 116 IP Cat5 KVM Switch
- RS232 Download Cable
- Rackmount Kit
- Owner's Manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

OVERVIEW	
UPC Code	654518211351
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / cm)	20.57 x 55.88 x 74.93
Shipping Dimensions (hwd / in.)	8.10 x 22.00 x 29.50
Shipping Weight (kg)	19.01
Shipping Weight (lbs.)	41.90
Unit Dimensions (hwd / in.)	1.7 x 17.6 x 25.2
Unit Dimensions (hwd / cm)	4.4 x 44.75 x 64
Unit Weight (lbs.)	40.1
Unit Weight (kg)	18.19
ENVIRONMENTAL	
Storage Temperature Range	-40 to 70 C / -40 to 158 F
Relative Humidity	10 to 90% RH
Operating Temperature	0 to 40 C / 32 to 104 F
COMMUNICATIONS	
Port Control	Hotkeys, OSD, Remote Toolbar
IP Remote Access	Yes
CONNECTIONS	
Number of Ports	16
Computer/Server Ports	16
PC/Server Connections	VGA; USB; PS/2
FEATURES & SPECIFICATIONS	
Number of Users	1
NIAP-Certified Secure	No
Cat5 KVM Switch	Yes
WARRANTY	
Product Warranty Period (Worldwide)	3-year limited warranty



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>