


# Fixed Wall Mount for 37" to 70" TVs and Monitors

MODEL NUMBER: DWF3770L

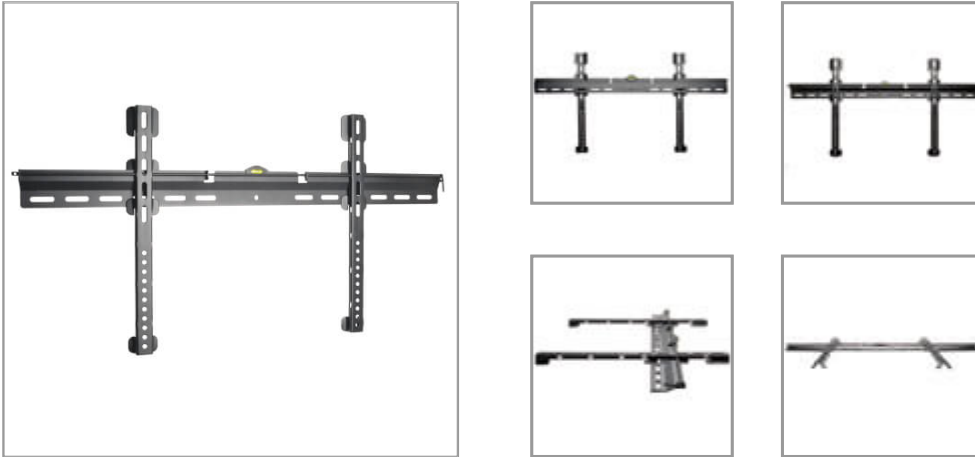

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants.

### Description

The VESA-compliant DWF3770L Fixed Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 37 to 70 inches. The low-profile mount is concealed behind the display to give a sleek, professional appearance. Frame is open for easy wall access. Mounting rails adjust horizontally to compensate for off-center wall studs. Built-in bubble level allows accurate display leveling. Durable all-metal frame with scratch-resistant powder-coated finish supports up to 143 lbs (64.9 kgs). Mounting hardware included. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm, 600 x 400 mm, 700 x 300 mm, 700 x 400 mm, 800 x 300 mm and 800 x 400 mm.

### Features

**Mounts Your TV or Monitor to the Wall** Fits most flat-panel televisions, monitors and other displays from 37 to 70 in. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Mounts out of sight behind display for sleek, professional appearance. Mounting hardware included.

**Durable Metal Construction** Supports up to 143 lbs (64.9 kgs). Open frame allows easy wall access. Adjustable mounting rails compensate for off-center wall studs. Built-in bubble level for accurate display leveling. Scratch-resistant powder-coated finish.

**VESA Compliance** Supports the following VESA mounting hole patterns: 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm, 600 x 400 mm, 700 x 300 mm, 700 x 400 mm, 800 x 300 mm and 800 x 400 mm.

## Specifications

| OVERVIEW             |              |
|----------------------|--------------|
| UPC Code             | 037332181701 |
| Device Compatibility | Monitor/HDTV |

### Highlights

- Fits most flat-panel displays from 37 to 70 in.
- Hangs out of sight for a sleek, professional appearance
- Adjustable mounting rails compensate for off-center wall studs
- Supports up to 143 lbs (64.9 kgs)

### Package Includes

- Wall plate
- (2) Adapter brackets
- Safety bar
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (8) Small spacers
- (4) Big spacers
- (4) Anchor bolts
- (4) Concrete anchors
- (4) D6 washers
- Owner's manual

| PHYSICAL                        |   |
|---------------------------------|---|
| Color                           | Black   |
| Material of Construction        | Steel   |
| VESA Pattern (mm)               | 300x200; 300x300; 300x400; 400x200; 400x300; 400x400; 500x200; 500x300; 500x400; 600x300; 600x400; 700x300; 700x400; 800x300; 800x400 |
| Motion                          | Fixed   |
| Mounting Location               | Wall  |
| Degrees of Motion               | Fixed   |
| Distance from Wall (in.)        | 1.18  |
| Distance from Wall (cm)         | 3   |
| Distance from Wall (mm)         | 30  |
| Minimum Screen Size (in.)       | 37  |
| Minimum Screen Size (cm)        | 93.98   |
| Maximum Screen Size (in.)       | 70  |
| Maximum Screen Size (cm)        | 177.8   |
| Maximum Weight Capacity (lbs.)  | 143   |
| Maximum Weight Capacity (kg)    | 65  |
| Number of Displays              | 1   |
| Shipping Dimensions (hwd / in.) | 6.30 x 1.75 x 35.50   |
| Shipping Dimensions (hwd / cm)  | 16.00 x 4.44 x 90.17  |
| Shipping Weight (lbs.)          | 5.00  |
| Shipping Weight (kg)            | 2.27  |
| Unit Dimensions (hwd / in.)     | 17.320 x 34.250 x 0.760   |
| Unit Dimensions (hwd / cm)      | 44 x 86.86 x 1.93   |
| Unit Weight (lbs.)              | 3.40  |
| Unit Weight (kg)                | 1.54  |
| Assembly Required               | Yes   |
| FEATURES & SPECIFICATIONS       |   |
| Antimicrobial                   | No  |
| Cord Management                 | No  |
| Tools Necessary                 | Yes   |
| Security Lock                   | No  |
| STANDARDS & COMPLIANCE          |   |
| Product Compliance              | RoHS; RoHS3; REACH  |



Powering Business Worldwide



| WARRANTY & SUPPORT                  |                         |
|-------------------------------------|-------------------------|
| Product Warranty Period (Worldwide) | 5-year limited warranty |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.