


T1 Shielded RJ48C Ethernet Cable (RJ45 M/M), 5 ft. (1.52 m) TAA

MODEL NUMBER: **N265-005**

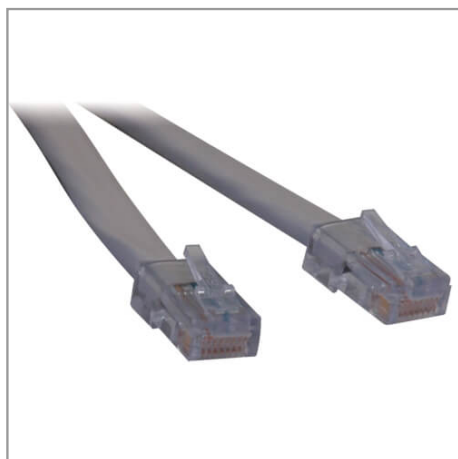

Highlights

- 22AWG, 100ohm T1 Rated Cable
- Connects your T1 CSU/DSU
- Meets ANSI T1.403 Cabling Requirement
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Package Includes

5-ft. (1.52 m) T1 Shielded RJ48C Patch Cable

Description

These T1, RJ45-RJ45 (RJ48C) Ethernet cables are constructed with premium Quabbin 9720, T1-certified cable. Two individually shielded, 22 AWG, 100 ohm pairs maximize the performance of your expensive T1 circuits and equipment. Beware of generic T1 Ethernet cables made with inexpensive Cat5 unshielded Ethernet cable. The American National Standards Institute (ANSI) states in ANSI T1.403 that T1 cable be constructed of two balanced pairs, 22 AWG Solid conductor, 100 ohm impedance, with a loss budget of 5.5 db. Straight-through wiring configuration available in 3-foot (0.9-meter), 5-foot (1.5-meter), 7-foot (2.1-meter) and 10-foot (3.1-meter) lengths. Custom lengths available. Consult your reseller. Also available in crossover wiring configuration. See N266-Series T1 Ethernet cables.

Features

- ANSI certified T1 cable, Levels 1, 1A, and 1C
- Complies with ANSI T1.403 Carrier-to-Customer Installation-DS1 Metallic Interface
- Straight through T1 wiring configuration
- Available in 3-ft. (0.91 m), 5-ft. (1.52 m), 7-ft. (2.13 m), and 10-ft. (3.05 m) stocked lengths
- Custom length cables available
- NEC (UL) Type CMR
- Available in Crossover wiring configurations
- 22AWG Solid Tinned Copper

Specifications

OVERVIEW	
UPC Code	037332150318
Technology	T1
CONNECTIONS	



Powering Business Worldwide

TRIPP LITE
SERIES

Side A - Connector 1	RJ45 (MALE)
Side B - Connector 1	RJ45 (MALE)
Crossover Wiring	No
Angled Connector	No
PHYSICAL	
Cable Jacket Color	Beige
Cable Jacket Rating	CMR
Cable Shielding	STP
Number of Conductors	4 Pair
Conductor Material	Solid Copper
Cable Length (ft.)	5
Cable Length (m)	1.52
Cable Length (in.)	60
Cable Length (cm)	152.4
Shipping Dimensions (hwd / in.)	0.10 x 9.30 x 10.30
Shipping Dimensions (hwd / cm)	0.25 x 23.62 x 26.16
Shipping Weight (lbs.)	0.10
Shipping Weight (kg)	0.05
FEATURES & SPECIFICATIONS	
Antibacterial	No
IP68 Rated	No
Snagless Connector	No
STANDARDS & COMPLIANCE	
Product Compliance	Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.