


## T1 Shielded RJ48C Patch Cable (RJ45 M/M), 7-ft.

MODEL NUMBER: N265-007

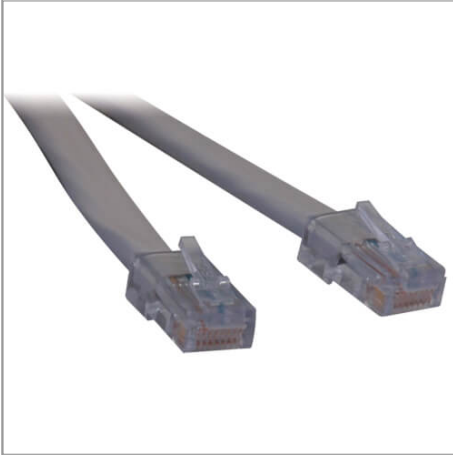

### Highlights

- 22AWG, 100ohm T1 Rated Cable
- Connects your T1 CSU/DSU
- Meets ANSI T1.403 Cabling Requirement
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

### Package Includes

7ft T1 Shielded RJ48C Patch Cable

### Description

Tripp Lite's T1, RJ45-RJ45 , ( RJ48C ) Patch Cables are constructed with premium Quabbin 9720, T1 certified cable. Two individually shielded, 22AWG, 100ohm pairs, maximize the performance of your expensive T1 circuits and equipment. Beware of generic T1 patch cables made with inexpensive Cat5 unshielded patch cable. The American National Standards Institute ( ANSI ) states in ANSI T1.403 that T1 cable be constructed of two balanced pairs, 22 AWG Solid conductor, 100ohm impedance, with a loss budget of 5.5db. Straight through wiring configuration available in 3ft, 5ft, 7ft, and 10ft lengths. Custom lengths available...consult your reseller. Also available in Crossover wiring configuration...see Tripp Lite N266- Series T1 patch cables.

### Features

- ANSI certified T1 cable, Levels 1, 1A, and 1C
- Complies with ANSI T1.403 Carrier-to-Customer Installation-DS1 Metallic Interface
- Straight through T1 wiring configuration
- Available in 3ft, 5ft, 7ft, and 10ft stocked lengths
- Custom length cables available
- NEC (UL) Type CMR
- Available in Crossover wiring configurations
- 22AWG Solid Tinned Copper

## Specifications

OVERVIEW	
UPC Code	037332150325
Technology	T1
CONNECTIONS	



Powering Business Worldwide



Side A - Connector 1	RJ45 (MALE)
Side B - Connector 1	RJ45 (MALE)
Angled Connector	No
<b>PHYSICAL</b>	
Cable Jacket Color	Beige
Cable Jacket Rating	CMR
Cable Shielding	STP
Number of Conductors	4 Pair
Conductor Material	Solid Copper
Cable Length (ft.)	7
Cable Length (m)	2.13
Cable Length (in.)	84
Cable Length (cm)	213.4
Shipping Dimensions (hwd / in.)	12.00 x 10.00 x 0.50
Shipping Dimensions (hwd / cm)	30.48 x 25.40 x 1.27
Shipping Weight (lbs.)	0.25
Shipping Weight (kg)	0.11
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antibacterial	No
IP68 Rated	No
Snagless Connector	No
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://triplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.