


## T1 Shielded RJ48C Crossover Cable (RJ45 M/M), 10 ft. (3.05 m) TAA

MODEL NUMBER: N266-010

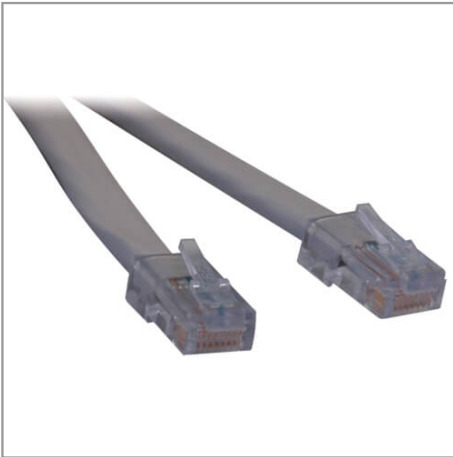

### Highlights

- 22AWG, 100ohm T1 Rated Cross-over Cable
- Connects your T1 CSU/DSU
- Meets ANSI T1.403 Cabling Requirement
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

### Package Includes

10-ft. (3.05 m) T1 Cross-over Shielded RJ48C Patch Cable

### Description

These T1, RJ45-RJ45 ( RJ48C ) cross-over Ethernet cables are constructed with premium Quabbin 9720, T1 certified cable. Two individually shielded, 22 AWG, 100 ohm pairs maximize the performance of your expensive T1 circuits and equipment. Beware of generic T1 Ethernet cables made with inexpensive Cat5 unshielded Ethernet cable. The American National Standards Institute (ANSI) states in ANSI T1.403 that T1 cable be constructed of two balanced pairs, 22 AWG Solid conductor, 100 ohm impedance, with a loss budget of 5.5 db. Cross-over wiring configuration available in 3-foot (0.9-meter), 5-foot (1.5-meter), 7-foot (2.1-meter) and 10-foot (3.1-meter) lengths. Custom lengths available. Consult your reseller. Also available in straight-through wiring configuration. See N265-Series T1 Ethernet cables.

### Features

- ANSI certified T1 cable, Levels 1, 1A, and 1C
- Complies with ANSI T1.403 Carrier-to-Customer Installation-DS1 Metallic Interface
- Cross-over T1 wiring configuration
- Available in 3-ft. (0.91 m), 5-ft. (1.52 m), 7-ft. (2.13 m), and 10-ft. (3.05 m) stocked lengths
- Custom length cables available
- NEC (UL) Type CMR
- Available also in Straight-through wiring configurations
- 22AWG Solid Tinned Copper

## Specifications

OVERVIEW	
UPC Code	037332150370
Technology	T1
CONNECTIONS	
Side A - Connector 1	RJ45 (MALE)



Powering Business Worldwide

TRIPP LITE  
SERIES

Side B - Connector 1	RJ45 (MALE)
Crossover Wiring	No
Connector Type	Crossover
Angled Connector	No
<b>PHYSICAL</b>	
Cable Jacket Color	Beige
Cable Jacket Rating	CMR
Cable Shielding	STP
Number of Conductors	4 Pair
Conductor Material	Solid Copper
Cable Length (ft.)	10
Cable Length (m)	3.05
Cable Length (in.)	120
Cable Length (cm)	304.8
Shipping Dimensions (hwd / in.)	12.00 x 10.00 x 0.50
Shipping Dimensions (hwd / cm)	30.48 x 25.40 x 1.27
Shipping Weight (lbs.)	0.34
Shipping Weight (kg)	0.15
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antibacterial	No
IP68 Rated	No
Snagless Connector	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	Trade Agreements Act (TAA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.