


10Gb Duplex Multimode 50/125 OM3 LSZH Fiber Patch Cable (Mini-LC / Mini-LC) - Aqua, 5M (16 ft.)

MODEL NUMBER: N838-05M

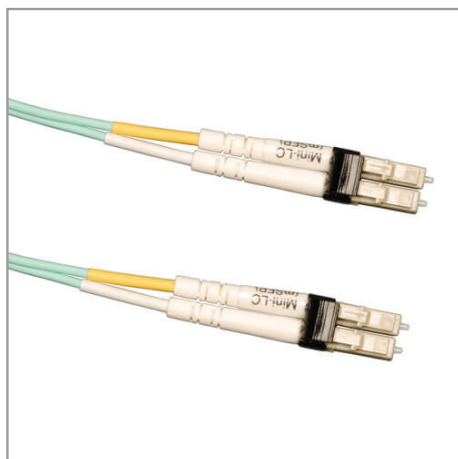

Highlights

- Mini-LC to Mini-LC Fiber Patch Cable, 5 Meter
- Designed for 10-Gig Ethernet applications...OM3 Rated
- For use with networking hardware employing mini-LC SFP transceivers
- Max 10Gb distance of 300 meters @850nm
- Low-Smoke, Zero Halogen (LSZH) Aqua jacket

Package Includes

- 5M (16-ft.) 10Gb Duplex MMF 50/125 OM3 LSZH Patch Cable (Mini-LC to Mini-LC) - Aqua

Features

- Mini-LC to Mini-LC Fiber Patch Cable, 5 Meter
- Designed for 10-Gig Ethernet applications...OM3 Rated
- For use with networking hardware employing mini-LC SFP transceivers
- Max 10Gb distance of 300 meters @850nm
- Low-Smoke, Zero Halogen (LSZH) Aqua jacket
- Use with Brocade FC8-64 and other Mini-LC SFP devices

Specifications

OVERVIEW	
UPC Code	037332165855
Technology	Multimode
Optical Mode	OM3
CONNECTIONS	
Side A - Connector 1	MINI LC DUPLEX (MALE)
Side B - Connector 1	MINI LC DUPLEX (MALE)
Endface Polish	PC
PHYSICAL	
Cable Jacket Color	Aqua
Connector Color	White; Black; Beige



Powering Business Worldwide

TRIPP-LITE
by **EAT•N**

Cable Jacket Material	LSZH
Cable Jacket Rating	OFNR
Clad Diameter (microns)	125
Core Diameter (microns)	50
Number of Fibers	2
Cable Length (ft.)	16.4
Cable Length (m)	5.00
Cable Length (in.)	196.9
Minimum Bend Radius	20MM (Dynamic); 10MM (Static)
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.09
Shipping Weight (kg)	0.04
ENVIRONMENTAL	
Operating Temperature Range	-4 to 140 °F (-20 to 60 °C)
Storage Temperature Range	-4 to 140 °F (-20 to 60 °C)
Operating Humidity Range	5% to 85% RH, Non-Condensing
Storage Humidity Range	35% to 65% RH, Non-Condensing
COMMUNICATIONS	
Network Compatibility	1 Gbps (Gigabit); 10 Gbps; 40 Gbps; 100 Gbps
Attenuation @ 850NM	3.0dB/Km
Insertion Loss	0.20dB
FEATURES & SPECIFICATIONS	
Push/Pull Tabs	No
Breakout	No
Trunk	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty



Powering Business Worldwide



1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.