


10Gb Duplex Multimode 50/125 OM3 LSZH Fiber Patch Cable (Mini-LC / Mini-LC) - Aqua, 10M (33 ft.)

MODEL NUMBER: **N838-10M**

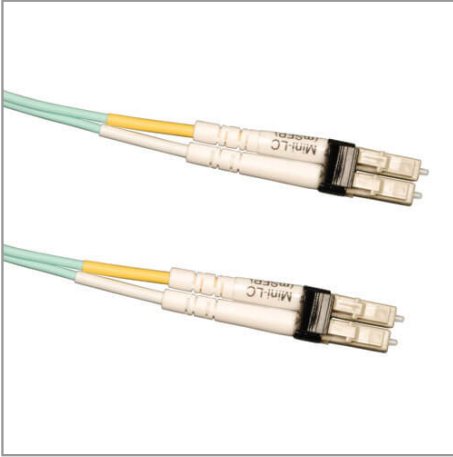

Highlights

- Mini-LC to Mini-LC Fiber Patch Cable, 10 Meter
- Designed for 10-Gig Ethernet applications...OM3 Rated
- For use with networking hardware employing mini-LC SFP transceivers
- Max 10Gb distance of 300 meters @850nm
- Low-Smoke, Zero Halogen (LSZH) Aqua jacket

Package Includes

- 10M (33-ft.) 10Gb Duplex MMF 50/125 OM3 LSZH Patch cable (Mini-LC to Mini-LC) - Aqua

Features

- Mini-LC to Mini-LC Fiber Patch Cable, 10 Meter
- Designed for 10-Gig Ethernet applications...OM3 Rated
- For use with networking hardware employing mini-LC SFP transceivers
- Max 10Gb distance of 300 meters @850nm
- Low-Smoke, Zero Halogen (LSZH) Aqua jacket
- Use with Brocade FC8-64 and other Mini-LC SFP devices

Specifications

OVERVIEW	
UPC Code	037332165879
Technology	Multimode
Optical Mode	OM3
CONNECTIONS	
Side A - Connector 1	MINI LC DUPLEX (MALE)
Side B - Connector 1	MINI LC DUPLEX (MALE)
Endface Polish	PC
PHYSICAL	
Cable Jacket Color	Aqua



Powering Business Worldwide



Connector Color	White; Black; Beige
Cable Jacket Material	LSZH
Cable Jacket Rating	OFNR
Clad Diameter (microns)	125
Core Diameter (microns)	50
Number of Fibers	2
Cable Length (ft.)	32.8
Cable Length (m)	10.00
Cable Length (in.)	393.7
Minimum Bend Radius	20MM (Dynamic); 10MM (Static)
Shipping Dimensions (hwd / in.)	0.25 x 5.30 x 6.30
Shipping Dimensions (hwd / cm)	0.64 x 13.46 x 16.00
Shipping Weight (lbs.)	0.20
Shipping Weight (kg)	0.09
ENVIRONMENTAL	
Operating Temperature Range	-4 to 140 °F (-20 to 60 °C)
Storage Temperature Range	-4 to 140 °F (-20 to 60 °C)
Operating Humidity Range	5% to 85% RH, Non-Condensing
Storage Humidity Range	35% to 65% RH, Non-Condensing
COMMUNICATIONS	
Network Compatibility	1 Gbps (Gigabit); 10 Gbps; 40 Gbps; 100 Gbps
Attenuation @ 850NM	3.0dB/Km
Insertion Loss	0.20dB
FEATURES & SPECIFICATIONS	
Push/Pull Tabs	No
Breakout	No
Trunk	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty



Powering Business Worldwide



1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.