


Keyspan Mini DisplayPort to Active VGA Adapter, Video Converter (M/F), White, 6-in. (15.24 cm)

MODEL NUMBER: P137-06N-VGA

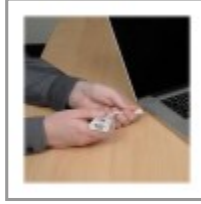

Connect a VGA monitor to a Mac or PC with a Mini Displayport output

Features

- Connect a VGA monitor to a Mac or PC with a Mini Displayport output
- Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Plug-and-play convenience—no drivers or software needed
- Supports computer video resolutions up to 1920 x 1200, and HD resolutions up to 1080p
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

Highlights

- Connect a VGA monitor to a Mac or PC with a Mini Displayport output
- Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Plug-and-play convenience—no drivers or software needed
- Supports computer video resolutions up to 1920 x 1200, and HD resolutions up to 1080p
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

System Requirements

- Mac or PC with a Mini Displayport port; Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Monitor with a VGA port
- Not for use with MST Hubs. For compatibility with MST Hubs, use a Displayport 1.2 compliant product such as P137-06N-VGA-V2

Package Includes

- Mini-DisplayPort to Active VGA Adapter

Specifications

| OVERVIEW | |
|----------------------|-------------------------|
| UPC Code | 037332158901 |
| Product Type | Video Adapter |
| Technology | VGA/SVGA; DisplayPort |
| CONNECTIONS | |
| Side A - Connector 1 | MINI DISPLAYPORT (MALE) |
| Side B - Connector 1 | HD15 (FEMALE) |
| PHYSICAL | |
| Color | White |



Powering Business Worldwide

TRIPP LITE
SERIES

| | |
|-------------------------------------|----------------------------------|
| Cable Length (ft.) | 0.5 |
| Cable Length (m) | 0.15 |
| Cable Length (in.) | 6 |
| Cable Length (cm) | 15.24 |
| Shipping Dimensions (hwd / in.) | 9.00 x 7.00 x 0.01 |
| Shipping Dimensions (hwd / cm) | 22.86 x 17.78 x 0.03 |
| Shipping Weight (lbs.) | 0.05 |
| Shipping Weight (kg) | 0.02 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 32° to 158°F (0° to 70°C) |
| Storage Temperature Range | 14° to 176°F (-10° to 80°C) |
| Operating Humidity Range | 10% ~ 85% RH |
| Storage Humidity Range | 5% ~ 90% RH |
| STANDARDS & COMPLIANCE | |
| Product Compliance | RoHS; Trade Agreements Act (TAA) |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 3-year limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.