


DisplayPort to VGA Active Adapter Cable (DP with Latches to HD15 M/M), 3 ft. (0.9 m)

MODEL NUMBER: P581-003-VGA

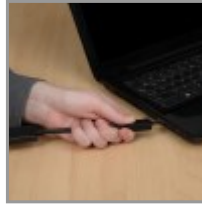

Connects a VGA monitor to a computer with Displayport using a single cable

Description

Tripp Lite's P581-003-VGA allows you to connect a desktop or laptop computer with a Displayport port to a VGA monitor. All in one 3-ft. (0.91 m) cable design requires no additional adapters or software....plug-and-play. Supports computer video resolutions up to 1920 x 1200, and HD video resolutions up to 1920 x 1080 (1080p). Unlike passive adapters, Active adapters convert both Single-Mode and Dual Mode (DP++) Displayport output. It is ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals.

Features

- 3-ft. (0.91 m) Displayport Male to VGA Male cable
- Supports computer video resolutions up to 1920 x 1200, and HD video resolutions up to 1920 x 1080 (1080p)
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

Specifications

OVERVIEW	
UPC Code	037332186201
Technology	VGA/SVGA; DisplayPort
Cable Type	Active
CONNECTIONS	
Side A - Connector 1	DISPLAYPORT (MALE)
Side B - Connector 1	HD15 (MALE)
Latching or Gripping Connector	Yes

Highlights

- Connect a Displayport computer port to a VGA monitor
- Supports computer video resolutions up to 1920 x 1200, and HD video resolutions up to 1920 x 1080 (1080p)
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

System Requirements

- VGA Monitor
- Computer with Displayport
- Not for use with MST Hubs. For compatibility with MST Hubs, use a Displayport 1.2 compliant product such as P581-003-VGA-V2

Package Includes

- 3-ft. (0.91 m) Displayport to Active VGA Cable, M/M



Powering Business Worldwide



PHYSICAL	
Color	Black
Cable Jacket Color	Black
Cable Length (ft.)	3
Cable Length (m)	0.91
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.14
Shipping Weight (kg)	0.06
FEATURES & SPECIFICATIONS	
IP68 Rated	No
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.