


SATA to eSATA Transition Cable (7Pin/7Pin), 3 ft. (0.91 m)

MODEL NUMBER: **P952-003**

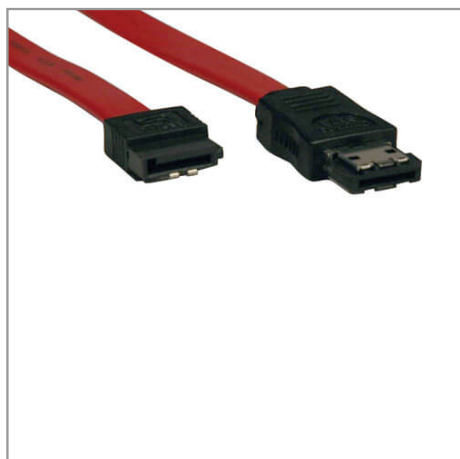

Highlights

- SATA Internal "L" to External eSATA "I" Cable - 3-ft.
- Supports data transfer rates of up to 6.0 Gbps
- Cable is shielded to protect against EMI/RFI line noise

Package Includes

- SATA to eSATA Transition Cable - 3-ft.

Features

- SATA Internal "L" to External eSATA "I" Data Cable - 3-ft.
- Supports data transfer rates up to 6 Gbps
- Fully shielded cable to protect against EMI/RFI line noise

Specifications

OVERVIEW	
UPC Code	037332140623
Technology	SATA/eSATA
CONNECTIONS	
Side A - Connector 1	7 PIN SATA (MALE)
Side B - Connector 1	7 PIN ESATA (MALE)
PHYSICAL	
Color	Red
Cable Length (ft.)	3
Cable Length (m)	0.91
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.13
Shipping Weight (kg)	0.06

WARRANTY & SUPPORT

Product Warranty Period (Worldwide)	Lifetime limited warranty
----------------------------------------	---------------------------

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.