


8 Right-Angle Outlet Vertical Power Strip, 120V, 15A, 15 ft. (4.57 m) Cord, 5-15P, 24 in.

MODEL NUMBER: PS2408RA

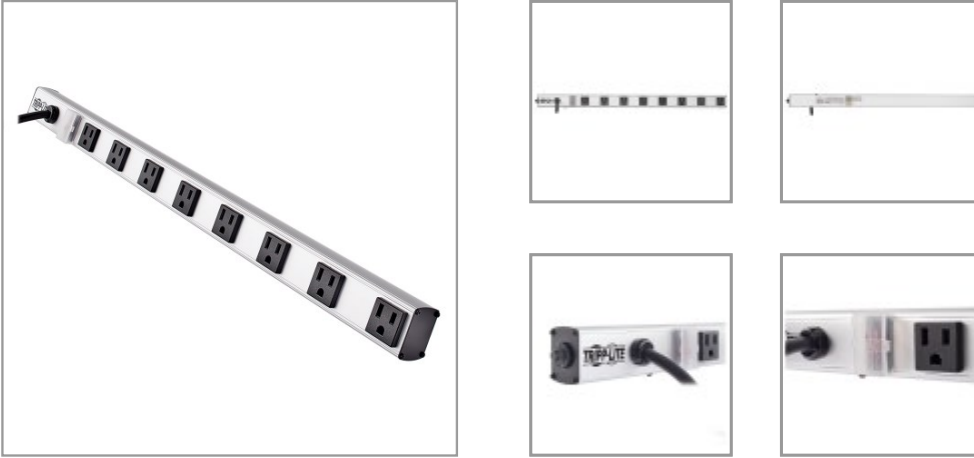

The PS2408RA power strip provides horizontal or vertical power distribution for rack-mount, raceway and workbench applications in a convenient 24-inch mountable housing.

Description

The PS2408RA provides a 15-amp, 120v power strip with 8 right-angle NEMA 5-15R receptacles in a rugged, all-metal, mountable housing. It allows for both vertical and horizontal mounting, making it ideal for a variety of uses including office, rack-mount, workbench, industrial and telecom applications. With a right angle NEMA 5-15P plug and 15-ft. (4.57 m) power cord, you don't have to install the PS2408RA next to outlets you already have; it can be mounted across the room and deliver reliable service where you need it most. A lighted and covered On/Off switch helps prevent accidental shut-offs, while a 15-amp circuit breaker guards against dangerous circuit overloads. Its sturdy all-metal extruded aluminum housing stands up to demanding network, laboratory or factory environments.

Features

Multi-Outlet Power Distribution

Vertical or Horizontal Moun

Extra Long Power Cord

Premium Safety Features

Heavy-Duty Housing

Specifications

OVERVIEW	
UPC Code	037332187451
INPUT	

Highlights

- Ideal for applications needing multiple convenience outlets for powering a variety of electronic equipment
- 24-in mountable housing with 8 right-angle NEMA 5-15R receptacles, right-angle plug and a 15-ft. (4.57 m) power cord
- Lighted, covered On/Off switch and 15-amp circuit breaker
- Sturdy construction and heavy-duty, all-metal housing

Package Includes

- PS2408RA Power Strip
- Mounting hardware
- Instruction manual



Powering Business Worldwide



Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	15A 120V
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	15
Right-Angle Plug	No
Input Cord Length (m)	4.57
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output Receptacles	(8) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(8) Yes
Right-Angle Outlets	Yes
Outlet Spacing	2.48 in.
USER INTERFACE, ALERTS & CONTROLS	
Switches	Lighted 2 position switch controls power to all outlets
Locking Switch Cover	Transparent on/off switch cover prevents accidental turn-off
PHYSICAL	
Color	Silver
Material of Construction	Aluminum
Power Cord Color	Black
Form Factors Supported	Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications
Housing Color	Silver
Included Mounting Accessories	Includes mounting clips
Mounting Holes or Slots	No
Outlets Measurement (Center to Center)	2.48 in.
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	2.40 x 4.61 x 28.19
Shipping Dimensions (hwd / cm)	6.10 x 11.71 x 71.60
Shipping Weight (lbs.)	3.14
Shipping Weight (kg)	1.42
Unit Dimensions (hwd / in.)	1.250 x 1.680 x 24.520



Powering Business Worldwide



Unit Dimensions (hwd / cm)	3.18 x 4.27 x 62.29
Unit Weight (lbs.)	2.71
Unit Weight (kg)	1.23
Outlet Spacing	2.48 in.
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Built-In Circuit Breaker	Yes
STANDARDS & COMPLIANCE	
Product Certifications	cUL Listed; UL 1363; UL Listed
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.