


# 24-Outlet Vertical Power Strip, 120V, 20A, L5-20P, 15 ft. (4.57 m) Cord, 72 in.

MODEL NUMBER: PS7224-20T

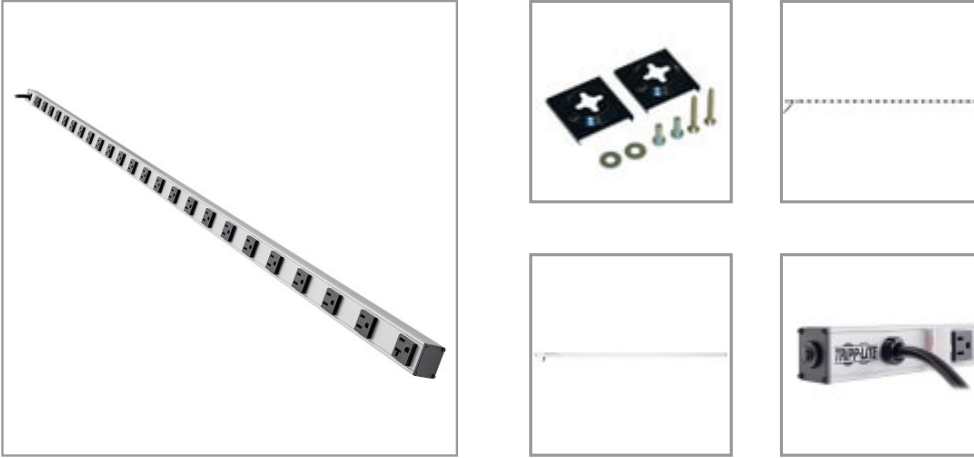

### Highlights

- 24 outlets
- Convenient and safe covered, on/off switch
- 20-amp circuit breaker
- 15-ft. (4.57 m) cord with locking L5-20 input plug
- 72" length

### Package Includes

- PS7224-20T
- Mounting hardware
- Instruction manual

### Description

PS7224-20T power strip offers 20A 120V multi-outlet AC power distribution in a convenient 72-inch mountable housing with NEMA L5-20 locking input plug. Offers horizontal or vertical power distribution in rack-mount, raceway and workbench applications. Includes 24 output receptacles with 2.8-inch center-to-center spacing, 15-foot (4.6-meter) AC line cord and lighted power switch with locking transparent cover to prevent accidental shutoff. Sturdy all-metal extruded aluminum housing stands up to demanding network, laboratory or factory environments.

### Features

- Sturdy all-metal 72 inch corded strip format with 2.795 inch center-to-center outlet spacing
- Included mounting hardware supports vertical or horizontal mounting in rack enclosures, raceways and more
- Includes 22 NEMA 5-15R and 2 NEMA 5-20R output receptacles
- Includes NEMA L5-20 twist-lock input plug connection
- Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications
- Lighted power switch with locking transparent cover prevents accidental shutoff
- 20 amp electrical capacity with circuit breaker
- 120V AC, 50/60Hz electrical compatibility

## Specifications

| OVERVIEW                           |              |
|------------------------------------|--------------|
| UPC Code                           | 037332042378 |
| INPUT                              |              |
| Nominal Input Voltage(s) Supported | 120V AC      |
| Recommended Electrical Service     | 20A 120V     |

|  |   |
|--|---|
| Input Cord Gauge Type                        | 12 gauge; SJT   |
| Voltage Compatibility (VAC)                  | 120   |
| Input Plug Type                              | NEMA L5-20P   |
| Input Cord Length (ft.)                      | 15  |
| Right-Angle Plug                             | No  |
| Input Cord Length (m)                        | 4.57  |
| Integrated Cord Clip                         | No  |
| <b>OUTPUT</b>                                |   |
| Frequency Compatibility                      | 50 / 60 Hz  |
| Output Receptacles                           | (2) 5-15/20R; (22) 5-15R  |
| Circuit Breaker (amps)                       | 20  |
| Transformer Accommodation                    | (12) Yes  |
| Right-Angle Outlets                          | No  |
| Outlet Spacing                               | 2.795 in.   |
| <b>USER INTERFACE, ALERTS &amp; CONTROLS</b> |   |
| Switches                                     | Lighted 2 position switch controls power to all outlets   |
| Locking Switch Cover                         | Transparent on/off switch cover prevents accidental turn-off  |
| <b>PHYSICAL</b>                              |   |
| Color  | Silver  |
| Material of Construction                     | Aluminum  |
| Power Cord Color                             | Black   |
| Form Factors Supported                       | Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications |
| Housing Color                                | Silver  |
| Included Mounting Accessories                | Includes mounting clips   |
| Mounting Holes or Slots                      | No  |
| Outlets Measurement (Center to Center)       | 2.83 in.  |
| Receptacle Color                             | Black   |
| Shipping Dimensions (hwd / in.)              | 3.50 x 2.50 x 76.00   |
| Shipping Dimensions (hwd / cm)               | 8.89 x 6.35 x 193.04  |
| Shipping Weight (lbs.)                       | 10.00   |
| Shipping Weight (kg)                         | 4.54  |
| Unit Dimensions (hwd / in.)                  | 1.250 x 72.000 x 1.500  |
| Unit Dimensions (hwd / cm)                   | 183 x 3.8 x 3.8   |
| Unit Weight (lbs.)                           | 6.6   |



Powering Business Worldwide



|                                      |                                |
|--------------------------------------|--------------------------------|
| Unit Weight (kg)                     | 2.99                           |
| Outlet Spacing                       | 2.795 in.                      |
| <b>FEATURES &amp; SPECIFICATIONS</b> |                                |
| Antimicrobial                        | No                             |
| Built-In Circuit Breaker             | Yes                            |
| <b>STANDARDS &amp; COMPLIANCE</b>    |                                |
| Product Certifications               | cUL Listed; UL 1363; UL Listed |
| Product Compliance                   | RoHS                           |
| <b>WARRANTY &amp; SUPPORT</b>        |                                |
| Product Warranty Period (Worldwide)  | Lifetime limited warranty      |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.