

Model: WWSS1332W



CAUTION: DO NOT EXCEED MAXIMUM LISTED WEIGHT CAPACITY (17.6 lb. / 8 kg). SERIOUS INJURY OR PROPERTY DAMAGE MAY OCCUR!

Este manual está disponible en español en la página de Eaton:
Tripplite.Eaton.com/support

Ce manuel est disponible en français sur le site Web de Eaton :
Tripplite.Eaton.com/support

Русскоязычная версия настоящего руководства представлена на веб-сайте компании Eaton по адресу: Tripplite.Eaton.com/support

Dieses Handbuch ist in deutscher Sprache auf der Eaton-Website verfügbar: [Tripplite.Eaton.com support](http://Tripplite.Eaton.com/support)



Powering Business Worldwide

PRODUCT REGISTRATION

Register your product today for a chance to win an ISOBAR® surge protector in our monthly drawing!


Tripplite.Eaton.com/warranty



Component Checklist



IMPORTANT: Ensure all parts according to the component checklist have been received prior to installation. If any parts are missing or faulty, visit Tripplite.Eaton.com/support for service.

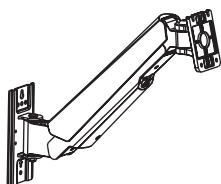


A

Bracket Arm
x1



B

 Support Mast
x1



C

Keyboard Shelf
x1



 
D

Decorative Cover
x2




E

M8 x 25
x2



F

 M4 x 12
x4




G

M5 x 12
x4



H

 M4 x 16
x4



I

M5 x 16
x4



J

D5 Washer
x4



K

8 x 5 Spacer
x4



L

D6 Washer
x3



M

6.3 x 55
Tapping Screw
x4



 
N

10 x 45 Anchor
x4



O

4 mm Hex Key
x1




P

6 mm Hex Key
x1

Assembly

- 1 Mount Bracket Arm to wall.

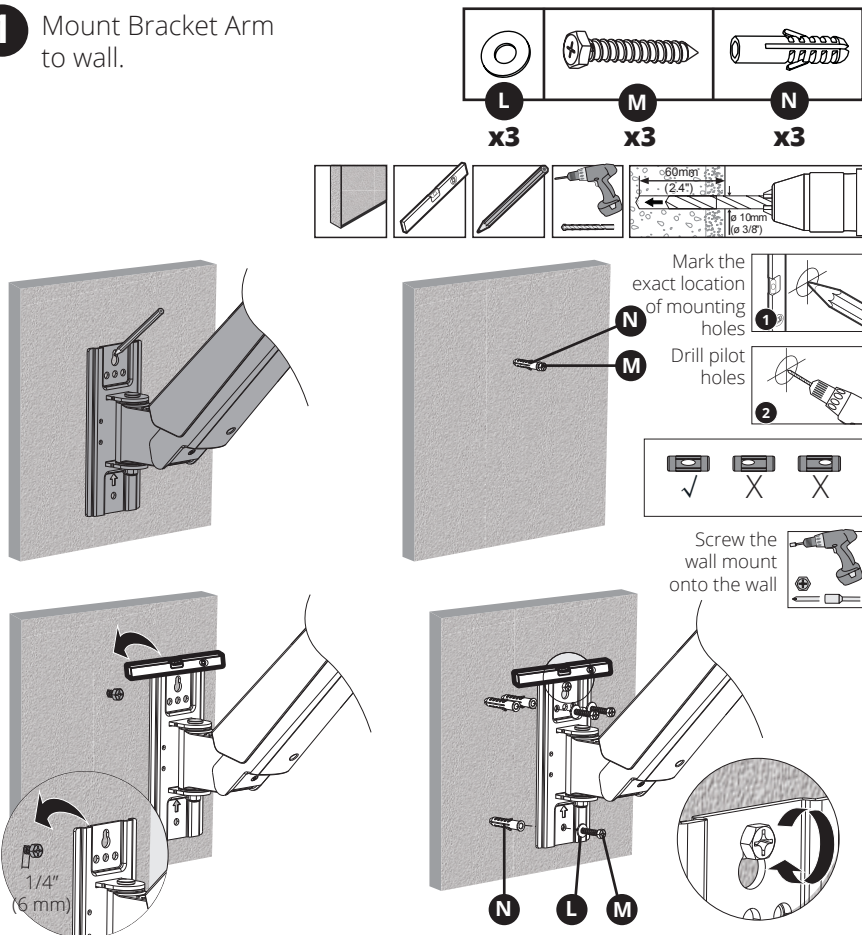


WARNING


- When mounting on a wood stud wall, make sure that mounting screws are anchored into the center of the studs. Use of a stud finder is highly recommended.
- When installing wall mounts onto a concrete masonry unit (also known as a CMU or "cinder block"), verify that the actual concrete thickness is at least 35 mm (1-3/8") in order to hold the concrete anchors. **DO NOT DRILL INTO MORTAR JOINTS!** Be sure to mount the wall mount with the included concrete anchors and anchor bolts onto solid sections of the blocks. The solid sections can generally be found 25 mm (1") toward the middle of the block from either end. An electric drill on a slow setting is suggested to drill the hole rather than a hammer drill, so as to avoid breaking out the back of the hole when entering a hollow section.
- Installers are responsible to provide hardware for other types of mounting situations.
- Installers must verify that the supporting surface will safely support the combined load of the equipment and all attached hardware and components.

Assembly


2 Install Decorative Covers.

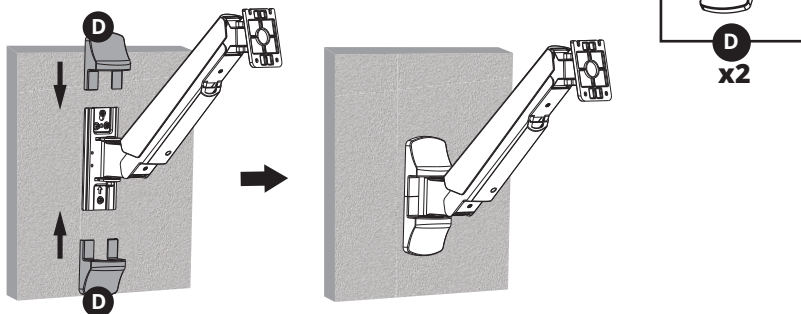

3 Remove VESA Plate from Support Mast.


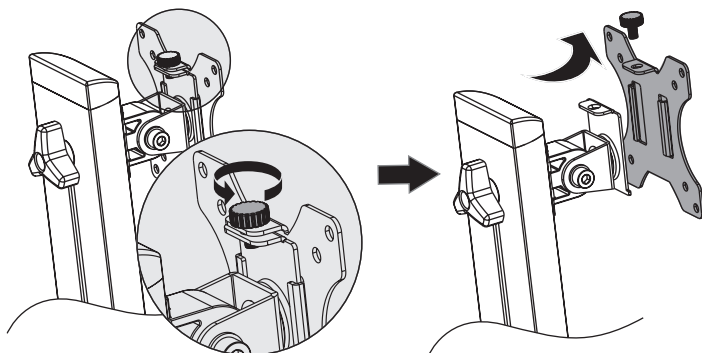


4 Attach Keyboard Shelf to Support Mast.



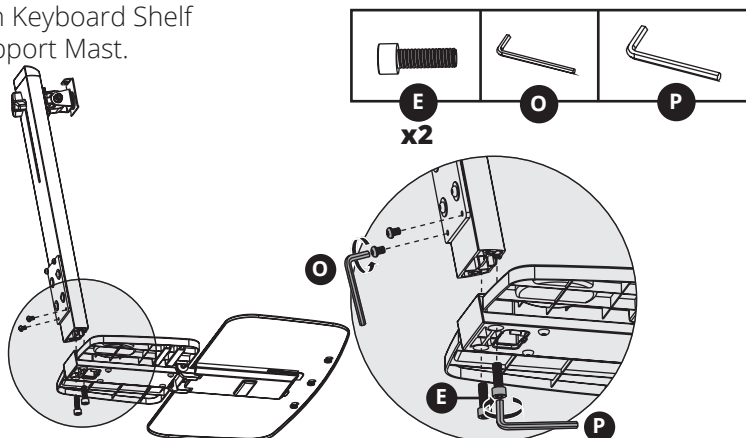


Assembly

 - 5** Attach Keyboard Shelf and Support Mast Assembly to Bracket Arm.

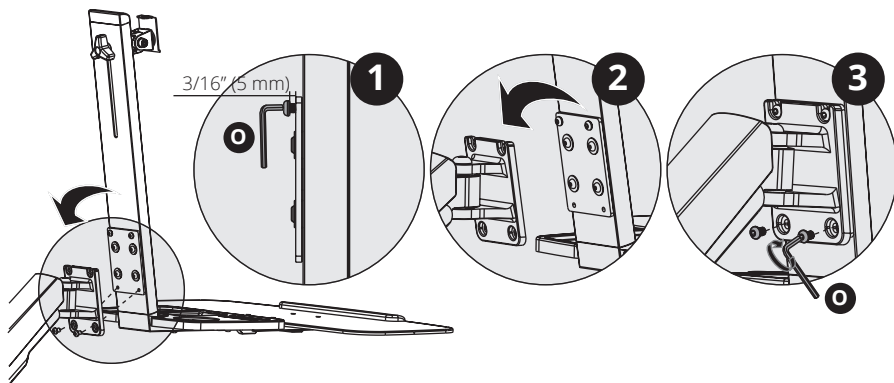

 - 6** Attach VESA plate to back of display.

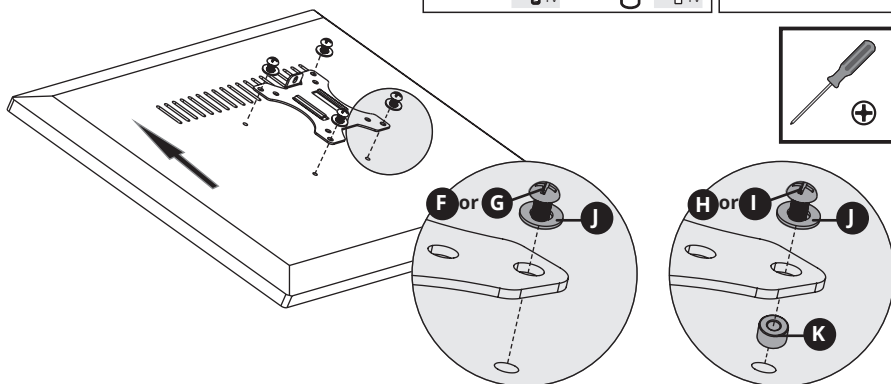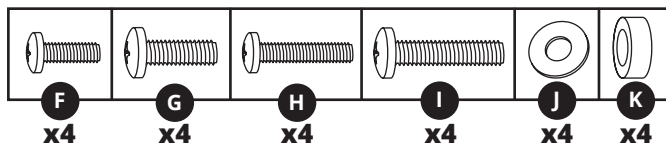


Note: Firmly secure the VESA plate to the display using the appropriate screws, washers and spacers (if necessary).

⚠ Do not over-tighten screws.


Assembly

- 7** Slide VESA plate and Display onto the Support Mast.

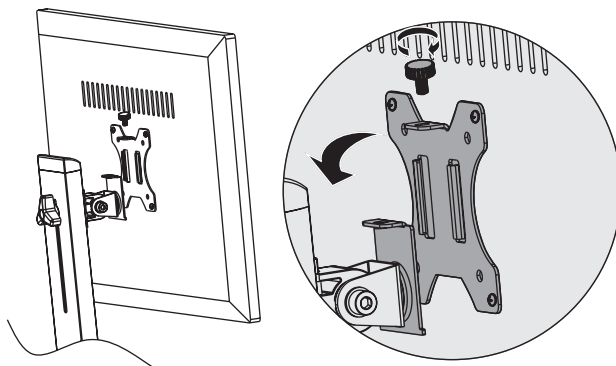

Using an assistant or mechanical lifting equipment, lift the display with attached VESA plate. Slide the VESA plate over the Support Mast bracket. Reattach the top knob to secure the VESA mount (removed in step 3).

- 8** Adjust Bracket Arm tension.

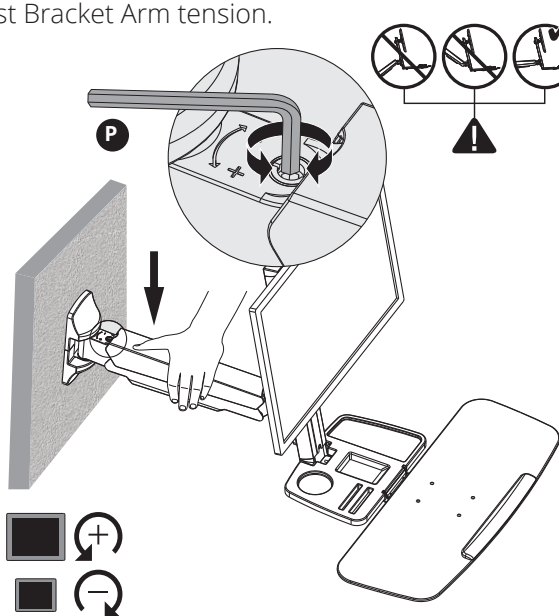


Keep the bracket arm level during tension adjustment. You may need to slightly loosen or tighten the adjustment screw using the provided 6 mm Hex Key, depending on the weight of display installed.

If display settles on its own, rotate adjustment screw towards the "+" symbol.

If display rises on its own, rotate adjustment screw towards the "-" symbol.


Assembly

- 9** Adjust to the desired location or tilt.

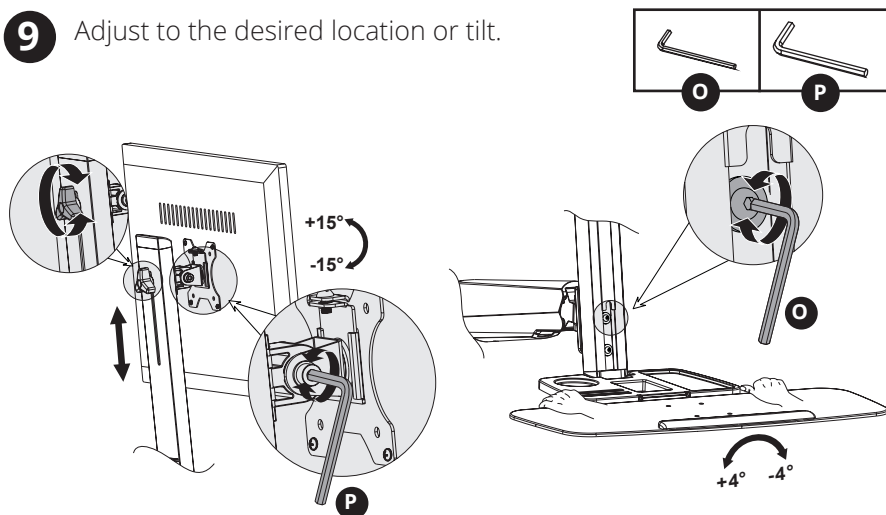

To correct the tilting angle, tighten the adjustment screws using the provided Hex Keys (or tighten the knob).

- 10** Keyboard Shelf adjusts at multiple angles.

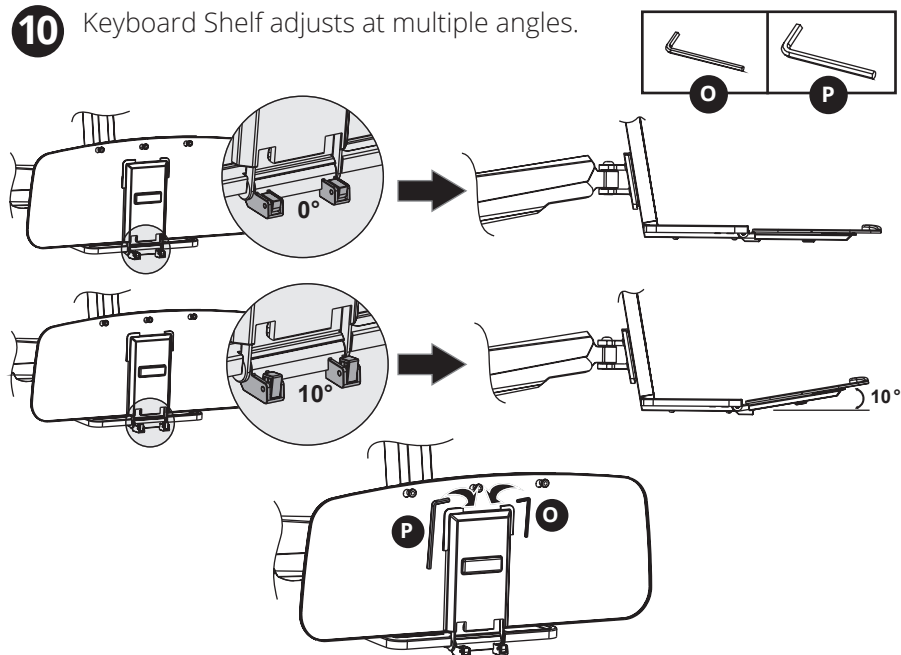

Assembly

Maintenance

- Check that the bracket is secure and safe to use at regular intervals (at least every three months).
- Please visit Tripplite.Eaton.com/support if you have any questions.

Warranty and Product Registration

5-YEAR LIMITED WARRANTY

We warrant our products to be free from defects in materials and workmanship for a period of five (5) years from the date of initial purchase. Our obligation under this warranty is limited to repairing or replacing (at its sole option) any such defective products. Visit Tripplite.Eaton.com/support/ product-returns before sending any equipment back for repair. This warranty does not apply to equipment which has been damaged by accident, negligence or misapplication or has been altered or modified in any way.

EXCEPT AS PROVIDED HEREIN, WE MAKE NO WARRANTIES, EXPRESS OR IMPLIED, INCLUDING WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE. Some states do not permit limitation or exclusion of implied warranties; therefore, the aforesaid limitation(s) or exclusion(s) may not apply to the purchaser.

EXCEPT AS PROVIDED ABOVE, IN NO EVENT WILL EATON BE LIABLE FOR DIRECT, INDIRECT, SPECIAL, INCIDENTAL OR CONSEQUENTIAL DAMAGES ARISING OUT OF THE USE OF THIS PRODUCT, EVEN IF ADVISED OF THE POSSIBILITY OF SUCH DAMAGE. Specifically, we are not liable for any costs, such as lost profits or revenue, loss of equipment, loss of use of equipment, loss of software, loss of data, costs of substitutes, claims by third parties, or otherwise.

PRODUCT REGISTRATION

Visit Tripplite.Eaton.com/warranty today to register your new product. You'll be automatically entered into a drawing for a chance to win a FREE Eaton Tripp Lite series product!*

*No purchase necessary. Void where prohibited. Some restrictions apply. See website for details.

Eaton has a policy of continuous improvement. Specifications are subject to change without notice.



Powering Business Worldwide

Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2023 Eaton
All Rights Reserved
Publication No. 23-06-147 / 93-3779_RevC / GG
November 2023

Eaton is a registered trademark.

All trademarks are property of their respective owners.