


Dual Flat-Panel Rail Wall Mount for 10" to 24" TVs and Monitors

MODEL NUMBER: **DMR1024X2**

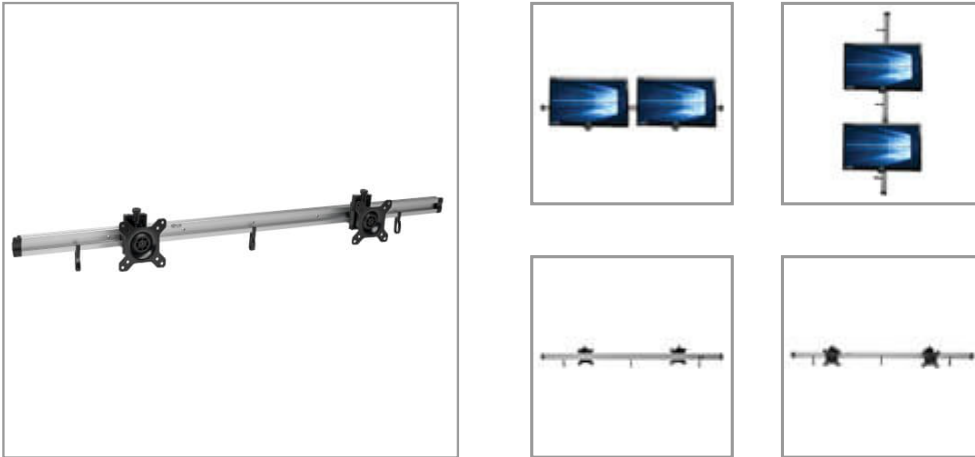

Low-profile rail mount hangs 2 flat-panel televisions, monitors or other displays on the wall. Recommended for video walls, menu boards and other displays in restaurants, bars, airports, hotels, offices and boardrooms.

Description

The VESA-compliant DMR1024X2 Dual Flat-Panel Rail Wall Mount allows you to mount two flat-panel televisions, monitors or other displays on the wall in either portrait or landscape mode. Recommended for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms, the low-profile mount fits most flat-panel displays from 10 to 24 inches.

Dual displays attach to VESA mounts that can slide closer or further apart along the rail for optimal viewing. The rail is concealed behind the displays for a sleek, professional appearance. Included cable guides attach to the rail to keep power cords out of the way.

Durable steel construction supports up to 18 lbs (8.2 kgs) per VESA mount. Mounting hardware is included. Conforms to VESA-compliant displays with either of the following mounting hole patterns: 75 x 75 mm and 100 x 100 mm.

Features

Mounts 2 Televisions or Monitors to the Wall

- Fits most flat-panel TVs, monitors and other displays from 10 to 24 in.
- Ideal for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms
- Designed for portrait or landscape mounting

Innovative Rail Design

- VESA mounts adjust independently along rail
- Rail conceals behind displays for sleek, professional appearance
- Cables attach to rail to prevent tangles and clutter
- Adjustable mounting rails match up with off-center wall studs
- Wall-mounting hardware included

Durable Steel Construction

- Supports up to 18 lbs (8.2 kgs) per VESA mount

Highlights

- Fits most flat-panel displays from 10 to 24 in.
- Designed for portrait or landscape mounting
- VESA mounts adjust independently along rail
- Durable steel construction
- Supports up to 18 lbs (8.2 kgs) per VESA mount

Package Includes

- Wall rail
- (2) VESA mounts
- (8) M4 x 12 screws
- (8) M4 x 30 screws
- (8) Spacers
- (3) Cable guides
- (5) Anchor bolts
- (5) Concrete anchors
- (5) Washers
- Owner's manual

VESA Compliance

- Supports the following VESA mounting hole patterns: 75 x 75 mm and 100 x 100 mm

Specifications

OVERVIEW	
UPC Code	037332202826
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black; Silver
Material of Construction	Steel
VESA Pattern (mm)	75x75; 100x100
Motion	Fixed
Mounting Location	Wall
Degrees of Motion	-15/+15 Tilt; 20 Swivel; 360 Rotate
Minimum Screen Size (in.)	10
Minimum Screen Size (cm)	25.4
Maximum Screen Size (in.)	24
Maximum Screen Size (cm)	60.96
Maximum Weight Capacity (lbs.)	18
Maximum Weight Capacity (kg)	8
Min/Max Arm Extension (in.)	3
Min/Max Arm Extension (cm)	7.62
Number of Displays	2
Shipping Dimensions (hwd / in.)	5.04 x 50.98 x 2.44
Shipping Dimensions (hwd / cm)	12.80 x 129.49 x 6.20
Shipping Weight (lbs.)	6.49
Shipping Weight (kg)	2.94
Unit Dimensions (hwd / in.)	4.730 x 50.000 x 3.350
Unit Dimensions (hwd / cm)	12 x 127 x 6
Unit Weight (lbs.)	5.08
Unit Weight (kg)	2.30
Assembly Required	Yes
FEATURES & SPECIFICATIONS	



Powering Business Worldwide



Antimicrobial	No
Cord Management	Yes
Tools Necessary	Yes
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.