


Portrait/Landscape Rotatable Fixed Flat-Screen Wall Mount for 37" to 70" TVs and Monitors

MODEL NUMBER: DWM3770PLX

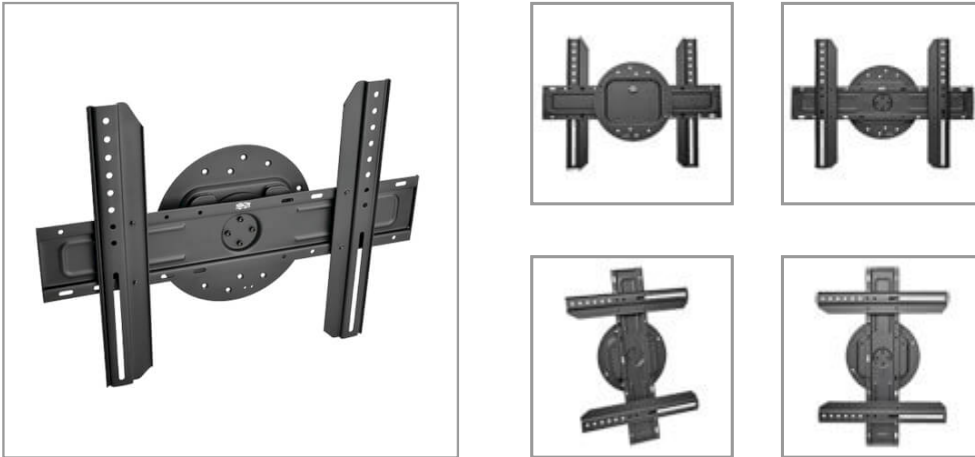

Hangs a flat-panel television, monitor or other display on the wall. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Rotates 90° for portrait and landscape viewing angles.

Description

The VESA-compliant DWM3770PLX Portrait/Landscape Rotatable Fixed Flat-Screen Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 37 to 70 inches.

The DWM3770PLX effortlessly rotates 90 degrees to position your display in either portrait or landscape mode to fit your environment and comfort level. The durable all-metal frame with scratch-resistant powder-coated finish supports up to 110 lbs (49.9 kgs).

To ease wall installation, the VESA plate attached to the display slides down into the wall-mounted plate. Mounting hardware is included. A built-in bubble level allows accurate wall plate leveling. The DWM3770PLX conforms to VESA-compliant displays with any of the following mounting hole patterns: 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm and 600 x 400 mm

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 37 to 70 in. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Mounting hardware included. Display plate slides down into wall plate for easy wall-mounting.

Allows 90° Rotation Spins effortlessly for portrait or landscape viewing.

Durable Metal Construction Supports up to 110 lbs (49.9 kgs). Scratch-resistant powder-coated finish blends with any décor. Built-in bubble level allows accurate display leveling.

VESA Compliance Supports the following VESA mounting hole patterns: 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm and 600 x 400 mm.

Highlights

- Fits most flat-panel displays from 37 to 70 in.
- Rotates smoothly 90° from portrait to landscape and vice versa
- Slide-in VESA plate for easy mounting
- Durable metal construction
- Supports up to 110 lbs (49.9 kgs)

Package Includes

- Wall plate
- Universal plate
- (2) Adapter brackets
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 10 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (4) D6 washers
- (8) Small spacers
- (4) Big spacers
- (4) Anchor bolts
- (4) Concrete anchors
- Hex key, 4 mm
- Owner's manual

Specifications



Powering Business Worldwide



| OVERVIEW | |
|--------------------------------------|---|
| UPC Code | 037332199874 |
| Device Compatibility | Monitor/HDTV |
| PHYSICAL | |
| Color | Black |
| Material of Construction | Steel |
| VESA Pattern (mm) | 200x100; 200x200; 200x300; 200x400; 300x200; 300x300; 300x400; 400x200; 400x300; 400x400; 500x200; 500x300; 500x400; 600x300; 600x400 |
| Motion | Full |
| Mounting Location | Wall |
| Degrees of Motion | 90 Rotate |
| Distance from Wall (in.) | 1.81 |
| Distance from Wall (cm) | 5 |
| Distance from Wall (mm) | 46 |
| Minimum Screen Size (in.) | 37 |
| Minimum Screen Size (cm) | 93.98 |
| Maximum Screen Size (in.) | 70 |
| Maximum Screen Size (cm) | 177.8 |
| Maximum Weight Capacity (lbs.) | 110 |
| Maximum Weight Capacity (kg) | 50 |
| Number of Displays | 1 |
| Shipping Dimensions (hwd / in.) | 2.00 x 24.90 x 10.80 |
| Shipping Dimensions (hwd / cm) | 5.08 x 63.25 x 27.43 |
| Shipping Weight (lbs.) | 13.36 |
| Shipping Weight (kg) | 6.06 |
| Unit Dimensions (hwd / in.) | 17.300 x 25.280 x 1.800 |
| Unit Weight (lbs.) | 9.75 |
| Unit Weight (kg) | 4.42 |
| Assembly Required | Yes |
| FEATURES & SPECIFICATIONS | |
| Antimicrobial | No |
| Cord Management | No |
| Tools Necessary | Yes |
| Security Lock | No |



Powering Business Worldwide



| STANDARDS & COMPLIANCE | |
|-------------------------------------|-------------------------|
| Product Compliance | RoHS; RoHS3; REACH |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 5-year limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.