


Tilt Wall Mount for 60" to 100" TVs and Monitors, UL Certified

MODEL NUMBER: DWT60100XX

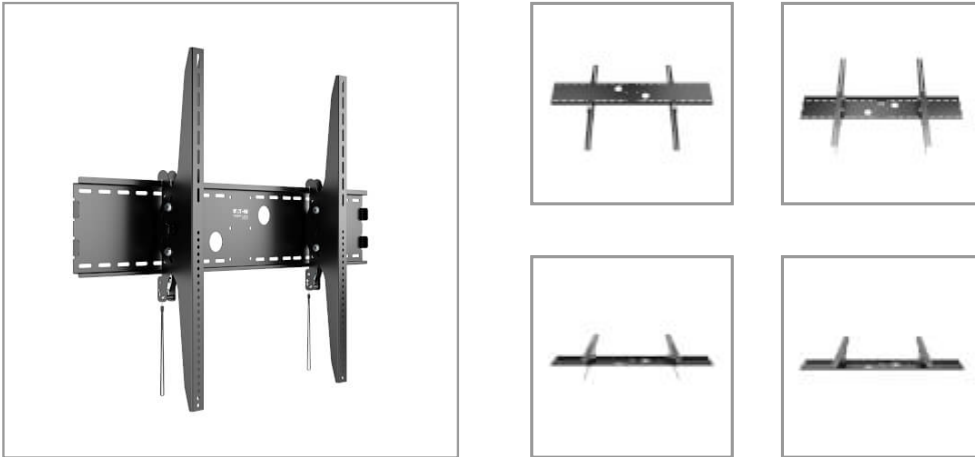

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Tilts to provide optimal viewing angles.

Description

The VESA-compliant DWT60100XX Tilt Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 60 to 100 inches. A -15° to $+15^{\circ}$ tilt capability minimizes glare and provides comfortable viewing from multiple angles.

Low-profile mount is concealed behind the display to give a sleek, professional appearance. Display brackets with connected straps adjust to compensate for off-center wall studs. Durable all-metal frame with scratch-resistant powder-coated finish supports up to 350 lbs (158.8 kgs). Mounting hardware included. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 100 x 100 mm, 100 x 200 mm, 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 300 x 700 mm, 300 x 800 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 400 x 700 mm, 400 x 800 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 500 x 600 mm, 500 x 700 mm, 500 x 800 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 600 x 700 mm, 600 x 800 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 700 x 700 mm, 700 x 800 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 800 x 700 mm, 800 x 800 mm, 900 x 400 mm, 900 x 500 mm, 900 x 600 mm, 900 x 700 mm, 900 x 800 mm, 1000 x 400 mm, 1000 x 500 mm, 1000 x 600 mm, 1000 x 700 mm and 1000 x 800 mm

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 60 to 100 in. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants Mounts out of sight behind display for sleek, professional appearance Mounting hardware included Tested in accordance with UL Standard 2442

Convenient One-Touch Adjustment -15° to $+15^{\circ}$ tilt capability provides comfortable viewing from multiple angles Improves viewing angles in applications where audience is below the display

Durable Metal Construction Supports up to 350 lbs (158.8 kgs) Adjustable display brackets with connected straps compensate for off-center wall studs Scratch-resistant powder-coated finish

VESA Compliance Supports the following VESA mounting hole patterns: 100 x 100 mm, 100 x 200 mm, 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 300 x 700 mm, 300 x 800 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 400 x 700 mm, 400 x 800 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 500 x 600 mm, 500 x 700 mm, 500 x 800

Highlights

- Fits most flat-panel displays from 60 to 100 in.
- Hangs out of sight for a sleek, professional appearance
- -15° to $+15^{\circ}$ tilt capability for wide range of motion
- Supports up to 350 lbs (158.8 kgs)

Package Includes

- Wall plate
- Mounting template
- (2) Adapter brackets
- (2) Tilt adjusting knobs
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (8) Small spacers
- (4) Big spacers
- (6) Anchor bolts
- (6) Concrete anchors
- (6) D6 washers
- Owner's manual



Powering Business Worldwide

TRIPP LITE
SERIES

mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 600 x 700 mm, 600 x 800 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 700 x 700 mm, 700 x 800 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 800 x 700 mm, 800 x 800 mm, 900 x 400 mm, 900 x 500 mm, 900 x 600 mm, 900 x 700 mm, 900 x 800 mm, 1000 x 400 mm, 1000 x 500 mm, 1000 x 600 mm, 1000 x 700 mm and 1000 x 800 mm

Specifications

OVERVIEW	
UPC Code	037332186683
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	1000x400; 1000x500; 1000x600; 1000x700; 1000x800; 100x100; 100x200; 200x100; 200x200; 200x300; 200x400; 200x500; 300x200; 300x300; 300x400; 300x500; 300x600; 300x700; 300x800; 400x200; 400x300; 400x400; 400x500; 400x600; 400x700; 400x800; 500x200; 500x300; 500x400; 500x500; 500x600; 500x700; 500x800; 600x300; 600x400; 600x500; 600x600; 600x700; 600x800; 700x300; 700x400; 700x500; 700x600; 700x700; 700x800; 800x300; 800x400; 800x500; 800x600; 800x700; 800x800; 900x400; 900x500; 900x600; 900x700; 900x800
Motion	Tilt
Mounting Location	Wall
Degrees of Motion	-15/+15 Tilt
Minimum Screen Size (in.)	60
Minimum Screen Size (cm)	152.4
Maximum Screen Size (in.)	100
Maximum Screen Size (cm)	254
Maximum Weight Capacity (lbs.)	350
Maximum Weight Capacity (kg)	159
Number of Displays	1
Shipping Dimensions (hwd / in.)	2.70 x 9.20 x 46.60
Shipping Dimensions (hwd / cm)	6.86 x 23.37 x 118.36
Shipping Weight (lbs.)	21.40
Shipping Weight (kg)	9.71
Unit Dimensions (hwd / in.)	32.760 x 44.880 x 5.120
Unit Dimensions (hwd / cm)	83.2 x 113.0 x 113.0
Unit Weight (lbs.)	17.36
Unit Weight (kg)	7.87
Assembly Required	Yes



Powering Business Worldwide

TRIPP LITE
SERIES

FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	No
Tools Necessary	Yes
Security Lock	No
STANDARDS & COMPLIANCE	
Product Certifications	UL 2442
Product Compliance	RoHS; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.